



B-498 Repositionable Vinyl Cloth Material

Color: White

Finish: Gloss

A repositionable vinyl cloth material for wire, cable, and component ID. The adhesive and cloth backing give excellent holding power, while being repositionable and removing cleanly.

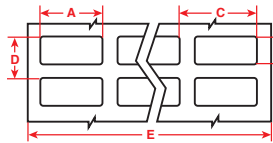


Figure 1

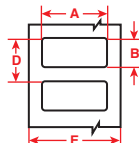


Figure 2

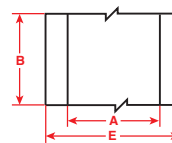


Figure 3



Performance Attributes: 

Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Horiz. Repeat C Inch (mm)	Vert. Repeat D Inch (mm)	Web Width E Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 3	THT-94-498-2	Vinyl Cloth	White	0.240 (6.1)	165 ft (50.8 m)	-	-	1.000 (25.4)	1	1 Roll Cont.	R4311
Fig. 1	THT-90-498-5	Vinyl Cloth	White	0.250 (6.4)	1.437 (36.5)	0.350 (8.9)	1.562 (39.7)	2.200 (55.9)	6	5,000	R4302
Fig. 3	THT-93-498-2	Vinyl Cloth	White	0.312 (7.9)	165 ft (50.8 m)	-	-	1.000 (25.4)	1	1 Roll Cont.	R4311
Fig. 3	THT-92-498-2	Vinyl Cloth	White	0.375 (9.5)	165 ft (50.8 m)	-	-	1.000 (25.4)	1	1 Roll Cont.	R4311
Fig. 1	THT-68-498-10	Vinyl Cloth	White	0.500 (12.7)	0.750 (19.1)	0.600 (15.2)	0.850 (21.6)	2.500 (63.5)	4	10,000	R4300
Fig. 1	THT-87-498-5	Vinyl Cloth	White	0.500 (12.7)	1.437 (36.5)	0.600 (15.2)	1.562 (39.7)	3.700 (94.0)	6	5,000	R4307
Fig. 1	THT-14-498-10	Vinyl Cloth	White	0.650 (16.5)	0.200 (5.1)	0.700 (17.8)	0.300 (7.6)	2.950 (74.9)	4	10,000	R4300
Fig. 1	THT-1-498-10	Vinyl Cloth	White	0.750 (19.1)	0.250 (6.4)	0.800 (20.3)	0.350 (8.9)	3.350 (85.1)	4	10,000	R4307
Fig. 1	THT-91-498-5	Vinyl Cloth	White	0.750 (19.1)	0.937 (23.8)	0.875 (22.2)	1.062 (27.0)	3.500 (88.9)	4	5,000	R4307
Fig. 1	THT-165-498-5	Vinyl Cloth	White	0.800 (20.3)	1.437 (36.5)	0.900 (22.9)	1.562 (39.7)	3.700 (94.0)	4	5,000	R4307
Fig. 1	THT-95-498-5	Vinyl Cloth	White	0.800 (20.3)	1.437 (36.5)	0.900 (22.9)	1.562 (39.7)	2.800 (71.1)	3	5,000	R4300
Fig. 1	THT-5-498-10	Vinyl Cloth	White	1.000 (25.4)	0.500 (12.7)	1.075 (27.3)	0.600 (15.2)	3.350 (85.1)	3	10,000	R4307
Fig. 2	THT-59-498-10	Vinyl Cloth	White	1.000 (25.4)	0.500 (12.7)	-	0.600 (15.2)	1.200 (30.5)	1	10,000	R4306
Fig. 1	THT-88-498-5	Vinyl Cloth	White	1.000 (25.4)	0.750 (19.1)	1.100 (27.9)	0.875 (22.2)	2.300 (58.4)	2	5,000	R4302
Fig. 1	THT-89-498-5	Vinyl Cloth	White	1.000 (25.4)	1.440 (36.5)	1.100 (27.9)	1.562 (39.7)	3.400 (86.4)	3	5,000	R4307
Fig. 2	THT-199-498-3	Vinyl Cloth	White	1.050 (26.7)	0.250 (6.4)	-	0.350 (8.9)	1.250 (31.8)	1	3,000	R4306
Fig. 2	THT-17-498-3	Vinyl Cloth	White	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	3,000	R4302
NOTICE BBP®12 PRINTER ONLY: The following part numbers ending with "-SC" are 1" Small Core Rolls for use in the BBP12 Printer only.											
Fig. 1	THT-90-498-2.5-SC	Vinyl Cloth	White	0.250 (6.4)	1.437 (36.5)	0.350 (8.9)	1.562 (39.7)	2.200 (55.9)	6	2,500	R4313
Fig. 3	THT-92-498-SC	Vinyl Cloth	White	0.375 (9.5)	165 ft (50.8 m)	-	-	1.000 (25.4)	1	1 Roll Cont.	R4313
Fig. 1	THT-68-498-5-SC	Vinyl Cloth	White	0.500 (12.7)	0.750 (19.1)	0.600 (15.2)	0.850 (21.6)	2.500 (63.5)	4	5,000	R4313
Fig. 1	THT-14-498-5-SC	Vinyl Cloth	White	0.650 (16.5)	0.200 (5.1)	0.700 (17.8)	0.300 (7.6)	2.950 (74.9)	4	5,000	R4313
Fig. 1	THT-1-498-5-SC	Vinyl Cloth	White	0.750 (19.1)	0.250 (6.4)	0.800 (20.3)	0.350 (8.9)	3.350 (85.1)	4	5,000	R4313
Fig. 1	THT-91-498-2.5-SC	Vinyl Cloth	White	0.750 (19.1)	0.937 (23.8)	0.875 (22.2)	1.062 (27.0)	3.500 (88.9)	4	2,500	R4313
Fig. 1	THT-165-498-2.5-SC	Vinyl Cloth	White	0.800 (20.3)	1.437 (36.5)	0.900 (22.9)	1.562 (39.7)	3.700 (94.0)	4	2,500	R6013
Fig. 1	THT-95-498-2.5-SC	Vinyl Cloth	White	0.800 (20.3)	1.437 (36.5)	0.900 (22.9)	1.562 (39.7)	2.800 (71.1)	3	2,500	R4313
Fig. 1	THT-88-498-2.5-SC	Vinyl Cloth	White	1.000 (25.4)	0.750 (19.1)	1.100 (27.9)	0.875 (22.2)	2.300 (58.4)	2	2,500	R4313
Fig. 2	THT-199-498-3-SC	Vinyl Cloth	White	1.050 (26.7)	0.250 (6.4)	-	0.350 (8.9)	1.250 (31.8)	1	3,000	R4313
Fig. 2	THT-17-498-1.5-SC	Vinyl Cloth	White	2.000 (50.8)	1.000 (25.4)	-	1.125 (28.6)	2.200 (55.9)	1	1,500	R4313

B-472 Topcoated Polyimide Wirewrap Material

Color: Various Finish: Matte

A thin polyimide material which features an advanced adhesive and topcoat design. This material is self-extinguishing, chemical resistant and able to withstand extreme environments including high temperatures. Provides a strong print performance yet remains flexible, conformable and repositionable for wire wrapping.

Performance Attributes: 



Diagram	Catalog #	Material	Color	Label Width A Inch (mm)	Label HeightB Inch (mm)	Vert. Repeat D Inch (mm)	Write On Height F Inch (mm)	Labels Per Row	Labels Per Pkg	Rec. Ribbon
Fig. 1	THT-2-472-10	Polyimide	White	0.900 (22.86)	0.250 (6.35)	1.125 (28.6)	3.350 (85.09)	3	10,000	R4300
Fig. 1	THT-5-472-10	Polyimide	White	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	3.350 (85.09)	3	10,000	R4300
Fig. 2	THT-29-472-10	Polyimide	White	1.250 (31.75)	0.375 (9.50)	1.300 (33.02)	2.750 (69.85)	2	10,000	R4300
Fig. 3	THT-106-472	Polyimide	White	2.000 (50.80)	300 ft. (91.4 m)	-	2.200 (55.88)	1	1 roll cont.	R4300
Fig. 3	THT-21-472	Polyimide	White	3.000 (76.2)	300 ft. (91.4 m)	-	3.200 (81.28)	1	1 roll cont.	R4300
Fig. 1	THT-14-472-10-YL	Polyimide	Yellow	0.650 (16.51)	0.200 (5.08)	0.300 (7.62)	2.950 (74.93)	4	10,000	R4300
Fig. 1	THT-1-472-10-YL	Polyimide	Yellow	0.750 (19.05)	0.250 (6.35)	0.800 (20.32)	3.350 (85.09)	4	10,000	R4300
Fig. 1	THT-5-472-10-YL	Polyimide	Yellow	1.000 (25.40)	0.500 (12.70)	1.075 (27.31)	3.350 (85.09)	3	10,000	R4300
Fig. 2	THT-29-472-10-YL	Polyimide	Yellow	1.250 (31.75)	0.375 (9.50)	1.300 (33.02)	2.750 (69.85)	2	10,000	R4300
Fig. 3	THT-105-472-YL	Polyimide	Yellow	1.500 (38.10)	300 ft. (91.4 m)	-	1.700 (43.18)	1	1 roll cont.	R4302
Fig. 3	THT-106-472-YL	Polyimide	Yellow	2.000 (50.80)	300 ft. (91.4 m)	-	2.200 (55.88)	1	1 roll cont.	R4300
NOTICE BBP®12 PRINTER ONLY: The following part numbers ending with “-SC” are 1” Small Core Rolls for use in the BBP12 Printer only.										
Fig. 3	THT-105-472-SC	Polyimide	White	1.500 (38.10)	200 ft. (60.96 m)	-	1.700 (43.18)	1	1 roll cont.	R4313
Fig. 3	THT-105-472-YL-SC	Polyimide	Yellow	1.500 (38.10)	200 ft. (60.96 m)	-	1.700 (43.18)	1	1 roll cont.	R4313