




Part Number : [734146500](#)

Product Description : MMCX Jack, Right-Angle, PCB Receptacle, Through Hole, Brass Body, Gold (Au) Plated, 2.16mm Leg Length, Tray, 50 Ohms

Series Number : 73414

Status : Active

Product Category : RF / Coaxial Connectors

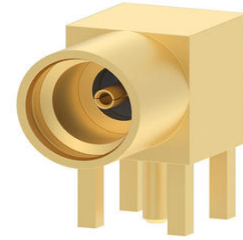

Documents and Resources

Drawings

[734146500_sd.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73414
Description	MMCX Jack, Right-Angle, PCB Receptacle, Through Hole, Brass Body, Gold (Au) Plated, 2.16mm Leg Length, Tray, 50 Ohms
Application	RF
Product Name	MMCX
Style	PCB
Type	Microminiature
UPC	889056897631

Electrical

Frequency	6 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 170 Vrms@Sea Level

Physical

Cable Attachment	N/A
Gender	Jack
Keying to Mating Part	N/A
Orientation	Right Angle
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
PCB Mounting	Through Hole
PCB Thickness - Recommended	1.68mm
Reverse Polar	No
Wire/Cable Type	N/A