




# BOARD-TO-BOARD HEADERS & RECEPTACLES

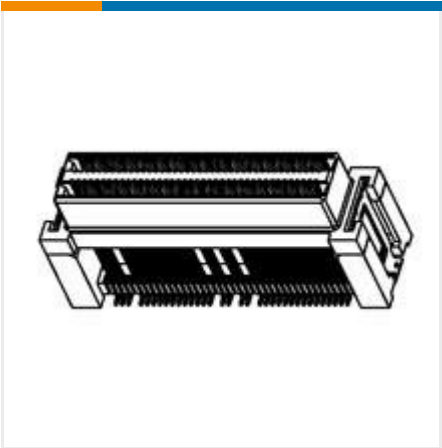

✓ Active

↓ **PRODUCT DRAWING**  
Japanese

↓ **3D PDF**

## TE CONNECTIVITY (TE) MICRO STACK REC ASSY 80P WITH TAPE

 
6376608-2  
TE Internal Number: 6376608-2

[Always EU RoHS/ELV Compliant](#)

Connector Style **Receptacle**

Number of Positions **80**

Packaging Method **Hard Tray**



### Product Drawings

[REC ASSEMBLY,0.6mm PITCH 80P MICRO STACK CONN](#)  
PDF [\(TIFF AVAILABLE\)](#)  
Japanese

[REC ASSEMBLY,0.6mm PITCH 80P MICRO STACK CONN](#)  
PDF [\(TIFF AVAILABLE\)](#)  
Japanese

CAD Files

Customer View Model

3D\_IGS.ZIP  
English

Customer View Model

3D\_STP.ZIP  
English

Customer View Model

2D\_DXF.ZIP  
English

3D PDF

PDF  
3D

Product Specifications

Product Specification

MICRO-STACK CONNECTOR

PDF  
Japanese

Qualification Test Report

MICRO-STACK CONNECTOR QUALIFICATION TEST REPORT

PDF  
Japanese

Product Environmental Compliance

TE Material Declaration

MD\_6376608-2\_12232014155\_dmtec

PDF  
English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Style

Receptacle

Applies To

Printed Circuit Board

Product Type

Connector

Configuration Features

Number of Positions

80

Preloaded

Yes

Electrical Characteristics

Voltage (VAC)

50

Contact Features

Contact Base Material

Copper Alloy

Solder Tail Contact Plating Material

Gold Flash

Housing Features

Housing Material

LCP (Liquid Crystal Polymer)

Dimensions

Height

13.58 mm [ .535 in ]

Usage Conditions	Operating Temperature Range (°C)	-55 – 85
Packaging Features	Packaging Method	Hard Tray
	Packaging Quantity	45
Product Compliance	<div>Statement of Compliance</div> <div>PDF</div> <div>VIEW ALL PRODUCT COMPLIANCE</div>	

