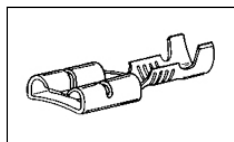


[My Cart](#) | [My Part Lists](#) | [Sign In/Register](#)[English \(Change\)](#)Search by Keyword or Part #

1544504-1 Product Details

Have a Question?

Chat with a Product
Information Specialist**1544504-1**

TE Internal Number: 1544504-1

[Active](#)[View 3D PDF](#)

FASTON Uninsulated Receptacles & Housings

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Product Classification = Connectors - Terminals and Splices
- Terminal
- Terminal Type = Receptacle
- Mating Area Interface Dimensions = 6.35 x 0.80 mm
- Board Mount = No

[View all Features](#)

Quick Links

[Check Pricing & Availability](#)
[Search for Tooling](#)
[Product Feature Selector](#)
[Contact Us About This Product](#)[Add to My Part List](#)[Request Sample](#)[Find Similar Products](#)[Buy Product](#)

Documentation & Additional Information		
Product Drawings: <ul style="list-style-type: none">CLIP DE SECURITE 6.35 capacite 1.5 a 3 mm2 (PDF, English)	Additional Information: <ul style="list-style-type: none">Product Line Information Related Products: <ul style="list-style-type: none">Tooling	
Catalog Pages/Data Sheets: <ul style="list-style-type: none">None Available		
Product Specifications: <ul style="list-style-type: none">None Available		
Application Specifications: <ul style="list-style-type: none">None Available		
Instruction Sheets: <ul style="list-style-type: none">None Available		
CAD Files: (CAD Format & Compression Information) <ul style="list-style-type: none">2D Drawing (DXF, Version B)3D Model (IGES, Version B)3D Model (STEP, Version B)		
List all Documents		

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: <ul style="list-style-type: none">Product Classification = Connectors - Terminals and SplicesProduct Type = TerminalTerminal Type = ReceptacleMating Area Interface Dimensions (mm [in]) = 6.35 x 0.80 [.250 x .031]Receptacle Style = StraightInsulation Support = Insulation SupportWire/Cable Type = StrandedInsulation Diameter (mm [in]) = 4.40 [.173]Insertion Force = LowMaterial = BrassFinish = NoneCrimp Type = F-Crimp	Body Related Features: <ul style="list-style-type: none">Weld Tab = WithoutWire Range (mm [AWG]) = 1.00-2.50² [17-13] Industry Standards: <ul style="list-style-type: none">RoHS/ELV Compliance = RoHS compliant, ELV compliantLead Free Solder Processes = Not relevant for lead free processRoHS/ELV Compliance History = Always was RoHS compliant Packaging Related Features: <ul style="list-style-type: none">Packaging Method = StripPackaging Quantity = 6,000 Other: <ul style="list-style-type: none">For Hermetic Header Tab = NoLine = MicrolockBrand = Tyco Electronics
Mechanical Attachment: <ul style="list-style-type: none">Board Mount = No	



Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat with Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage Your Account](#)

Sign up for our eNewsletter

Enter your email address

Follow Us On:

Twitter| Facet Flickr| Linke| YouTi

Visit Us On:



