




+ CONNECTORS

AUTOMOTIVE, TRUCK, BUS, & OFF-ROAD HOUSINGS

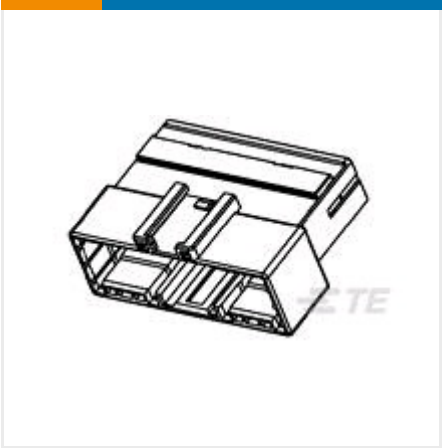

✓ Active

TE CONNECTIVITY (TE)  
**090III 22P CAP ASSY**  
Multilock Connector System

936154-1  
TE Internal Number: 936154-1

- EU RoHS Compliant
- EU ELV Compliant
- Connector Style Housing for female terminals
- Mating Tab Width 2.3 mm [ .09 in ]
- Connector System Wire-to-Wire
- Number of Positions 22
- Centerline (Pitch) 4 mm [ .157 in ]

↓ **PRODUCT DRAWING**  
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings  
**090 III 22P CAP ASS'Y**  
PDF  
English

CAD Files  
**Customer View Model**  
2D\_DXF.ZIP  
English

**3D PDF**  
PDF  
3D

Customer View Model

3D\_IGS.ZIP

English

Customer View Model

3D\_STP.ZIP

English

Product Specifications

Product Specification

090III 22P CAP ASSY D-GRY

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

**Connector Style** Housing for female terminals

**Connector System** Wire-to-Wire

**Sealable** No

**Hybrid Connector** No

**Strain Relief** No

**Row-to-Row Spacing** 5 mm [ .197 in ]

Configuration Features

**Number of Positions** 22

**Number of Rows** 2

Body Features

**Color** Natural

**Body Material** PBT GF

Contact Features

**Mating Tab Width** 2.3 mm [ .09 in ]

Mechanical Attachment

**Mounting Feature** No

**Terminal Position Assurance** No

**Polarized** Yes

Housing Features

**Centerline (Pitch)** 4 mm [ .157 in ]

Dimensions

**Width** 19.7 mm [ .7755 in ]  
**Height** 34 mm [ 1.3386 in ]  
**Length** 49.4 mm [ 1.9449 in ]

Operation/Application

**Circuit Application** Signal

Packaging Features

**Packaging Method** Bag

**Packaging Quantity** 130

Other

**Connector Position Assurance Capable** No

**Serviceable** No

**PRODUCT COMPLIANCE**



Statement of Compliance

**Statement of Compliance**

PDF