




+ RELAYS, CONTACTORS & SWITCHES
MID-RANGE

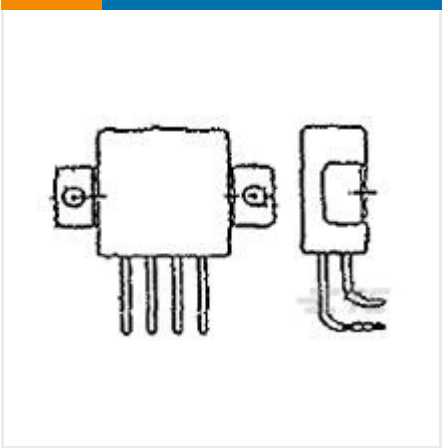

✓ Active

TE CONNECTIVITY (TE)
FCA-215-HZ4
CII | FCA 10-25 Amp Relay

FCA-215-HZ4
TE Internal Number: 4-1617752-5

- Not EU RoHS Compliant
- Not EU ELV Compliant
- Contact Arrangement 2 Form C, DPDT, 2 C/O
- Coil Suppression Diode With
- Auxiliary Contacts Without
- Terminal Plating Tin-Lead
- Contact Current Rating (A) 15

↓ PRODUCT DRAWING
English

↓ 3D PDF

DOCUMENTATION

Product Drawings

MSD RELAY
PDF
English

CAD Files

3D PDF
PDF
3D

Customer View Model
2D_DXF.ZIP
English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

- Terminal Configuration** Solder Pins, 90°
- Relay Type** Military/Aerospace Mid-Range
- Product Type** Relay
- Enclosure Type** Hermetically Sealed

Electrical Characteristics

- Coil Suppression Diode** With
- Coil Voltage Rating (VDC)** 28
- Coil Resistance (Ω)** 320
- Back EMF Suppression** With
- Coil Magnetic System** Polarized, Monostable
- Shock** 200G's, 6ms
- Actuating System** DC
- Vibration** 30G's, 33 – 3000Hz

Contact Features

- Contact Arrangement** 2 Form C, DPDT, 2 C/O
- Auxiliary Contacts** Without
- Terminal Plating** Tin-Lead
- Contact Current Rating (A)** 15
- Contact Base Material** Silver Cadmium Oxide

Mechanical Attachment

- Mounting Type** No Brackets

Usage Conditions

- Operating Temperature Range (°C)** -70 – 125

PRODUCT COMPLIANCE



Statement of Compliance

- Statement of Compliance**
- PDF

