


# Specifications

## Eaton PTS120630V012

Eaton Bussmann series PTS1206 PTC resettable fuse, 0.12 A hold current, 30 Vdc



Photo is representative

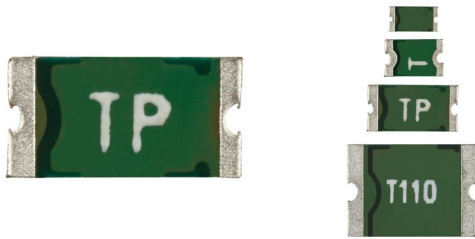

### General specifications

|                             |                                                   |
|-----------------------------|---------------------------------------------------|
| <b>PRODUCT NAME</b>         | Eaton Bussmann series PTS1206 PTC resettable fuse |
| <b>CATALOG NUMBER</b>       | PTS120630V012                                     |
| <b>UPC</b>                  | 051712351607                                      |
| <b>PRODUCT LENGTH/DEPTH</b> | 3.25 mm                                           |
| <b>PRODUCT HEIGHT</b>       | 0.7 mm                                            |
| <b>PRODUCT WIDTH</b>        | 1.65 mm                                           |
| <b>PRODUCT WEIGHT</b>       | 0.015 g                                           |
| <b>COMPLIANCES</b>          | RoHS Compliant<br>TUV                             |
| <b>CERTIFICATIONS</b>       | cURus                                             |

## Product specifications

### USED WITH

Medical equipment,  
Telecommunications,  
computers and  
peripherals  
Medical equipment,  
telecommunications,  
computers and  
peripherals

|                 |                     |
|-----------------|---------------------|
| AMPERAGE RATING | 0.12 A hold current |
|-----------------|---------------------|

|                |                |
|----------------|----------------|
| FUSE INDICATOR | Non-indicating |
|----------------|----------------|

|                 |                    |
|-----------------|--------------------|
| MOUNTING METHOD | Resettable surface |
|-----------------|--------------------|

|                |          |
|----------------|----------|
| PACKAGING TYPE | Standard |
|----------------|----------|

|          |      |
|----------|------|
| QUANTITY | 5000 |
|----------|------|

|                |        |
|----------------|--------|
| VOLTAGE RATING | 30 Vdc |
|----------------|--------|

|      |            |
|------|------------|
| TYPE | Electronic |
|------|------------|

|                  |                         |
|------------------|-------------------------|
| SPECIAL FEATURES | Halogen free, lead free |
|------------------|-------------------------|

|             |                     |
|-------------|---------------------|
| APPLICATION | Electronic circuits |
|-------------|---------------------|

## Resources

### SPECIFICATIONS AND DATASHEETS

[Eaton Specification Sheet -  
PTS120630V012](#)

[Eaton PTS1206 6 60 volt dc  
surface mount resettable  
ptc data sheet](#)

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



### Eaton Corporation plc

Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
[Eaton.com](#)

© 2025 Eaton. All Rights Reserved.

Follow us on social media to get the  
latest product and support  
information.

