





Part Number: SM150506-2	DRAWN CJ	4/25/2017
	CHECKED P.D.	4/28/2017
	APPROVED C.E.	4/28/2017
Description: Dynamic Speaker		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

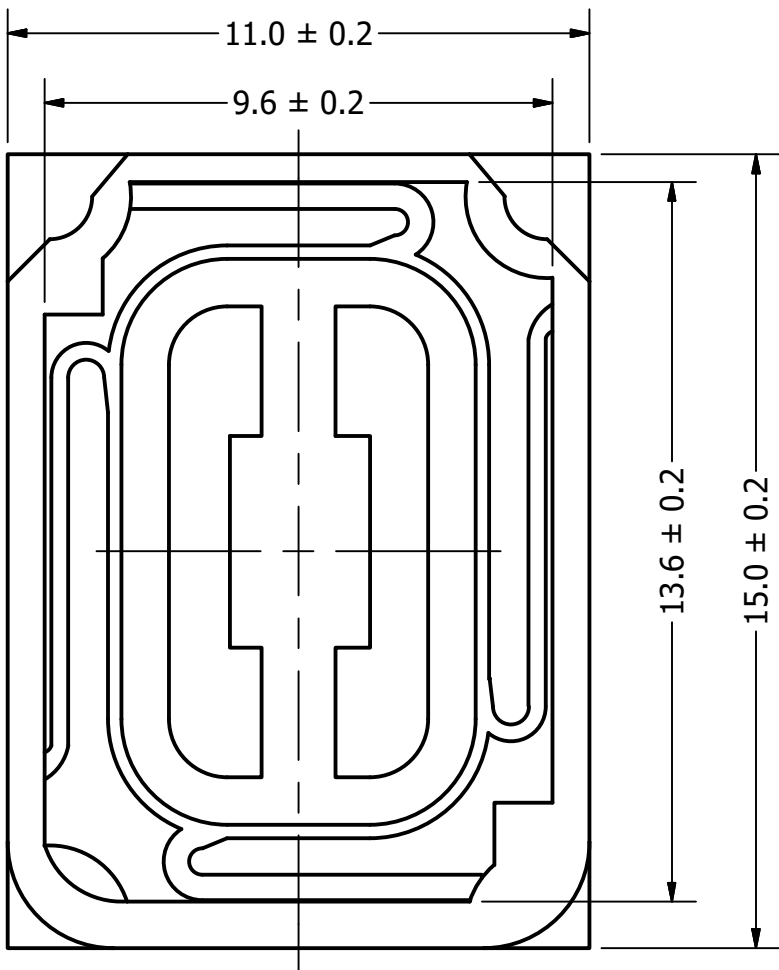

Side View

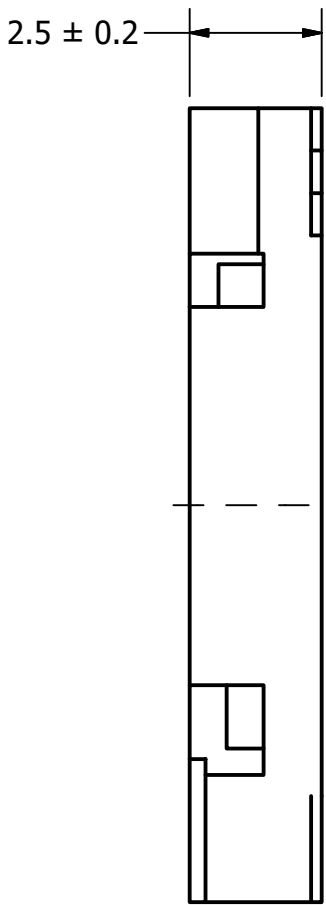

Bottom View

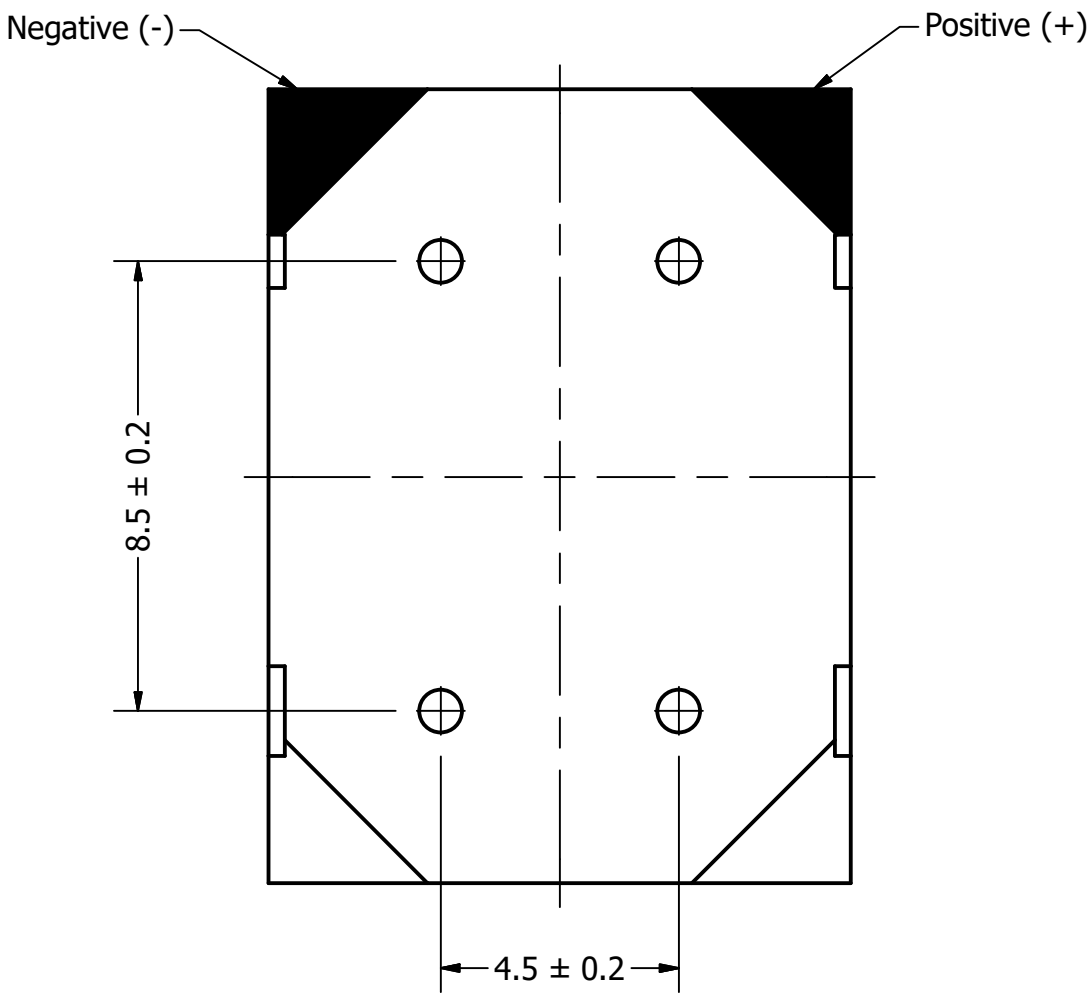

Items	Specifications	Conditions				
Sound Pressure Level	92 ± 3	dB (@ 10cm)				
Resonant Frequency	550	Hz	REVISION HISTORY			
Frequency Range	550 ~ 20,000	Hz	REV	DESCRIPTION	DATE	APPROVED
Nominal Power	0.7	W		Released from Engineering	4/28/2015	J.S.
Max. Power	1	W	1	Updated to new template	4/28/2017	C.E.
Impedance	6	Ω	NOTES			
Cone Material	Mylar		1) All dimensions are in mm unless otherwise noted			
Mount Type	Flush Mount		2) All tolerances are ± 0.3 mm unless otherwise noted			
Storage Temperature	-20 ~ +70	°C	3) All parts meet RoHS			
Operating Temperature	-20 ~ +70	°C	4) Subject to change or redrawn without notice			
Weight	1.6	g				