


Part number description :

10134254-XXXLF

LF: Lead Free, RoHs compliant, see note

XXX : Color ref or/and version

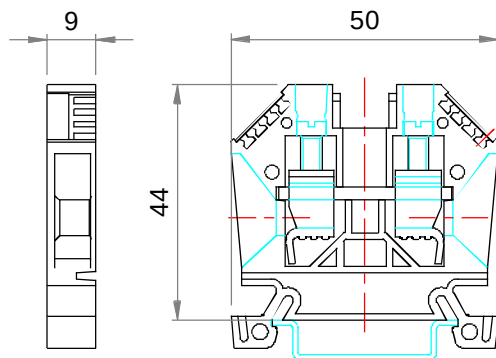

Note : THIS PRODUCT MEETS EUROPEAN UNION DIRECTIVES
AND OTHER COUNTRY REGULATIONS AS PER GS-47-0004

TECHNICAL DATA / DIMENSIONS

Dimensions	
Width mm	9.0
Length mm	50.0
Height mm	44.0
Mounting type (EN 60715)	Omega TH35
Technical data	
Maximum load current	65A
Insulating material	PA
Self-extinguishing degree acc. to UL94	V2
Rated surge voltage	8kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Nominal Voltage	1000V
Nominal Current	57A
Connection data	
Conductor cross-section solid min/max	1.50 / 16 mm ²
Conductor cross-section stranded min/max	1.50 / 10 mm ²
AWG min/max	20-6AWG
Max conductor cross-section stranded with ferrule with plastic sleeve	10 mm ² / L=18 mm
Stripping length	max 12 mm
Screw	M4
Tightening torque	1,2Nm / 20 Lb-In

APPROVALS



AWG 20-6 - 600V - 65A



RINA

EN60947-7-1 10mm² - 1000V - 57A

ACCESSORIES

Item	Description
Marking	
10134398-001LF	Blank single-digit marking tags
10134398-002LF+	Printed single-digit marking tags numbered : 1÷0
10134398-011LF	
10134398-012LF+	Printed single-digit marking tags with letter: A÷Z
10134398-041LF	
10134399-001LF	Marking tag adapter
10134400-001LF	Blank Marking tags
10134401-001LF	Blank Marking tags

DIN RAIL system - Mounting and Installation material

10134392-001LF	Steel Omega Rail TH35x7,5mm -2mt length
10134393-001LF	Slotted Steel Omega Rail TH35x7,5mm -2mt length
10134394-001LF	Steel Omega Rail TH35x15mm -2mt length
10134395-001LF	Slotted Steel Omega Rail TH35x15mm -2mt length
10134387-001LF	Angled support bracket
10134389-001LF	End Bracket for TH35 Omega rail -Width 9mm
10134390-001LF	End Bracket for TH35 Omega rail -Width 6mm
10134391-001LF	Fast-snap End Bracket for TH35 Omega rail

Additional items

10134260-001LF	End Plate for SCREW Terminal Blocks 6/10
10134264-001LF	Separator for SCREW Terminal Blocks 6/10
10134268-001LF	Cover for SCREW Terminal Blocks 6/10
10134265-001LF	Screw Jumper bar for SCREW Terminal Block 10
10134276-001LF	Red test plug adapter
10134276-002LF	Black test plug adapter

spec ref				dir	Aymeric Souidy	11-06-2015	projection		mm		size	A3	scale	1:1
tolerance std	TOLERANCES UNLESS OTHERWISE SPECIFIED			eng	Aymeric Souidy	11-06-2015					ecn no			
ISO 406				chr										
ISO 1101				appr	Aymeric Souidy	11-06-2015	product family	DIN Terminal Block	rel level					
surface  ISO 1302	linear	0.X	± 0.3		title	SCREW Terminal block 10	dwg no	10134254	rev	A				
		0.XX	± 0.1											
		0.XXX	± 0.05											
	angular	0°	± 2°								www.fcicom	cat. no.	-	Product customer drawing