





DB UNLIMITED

Part Number:	DRAWN	4/5/2021
	CJ	
	CHECKED	4/5/2021
Description:	P.D.	
	APPROVED	4/5/2021
	J.S.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

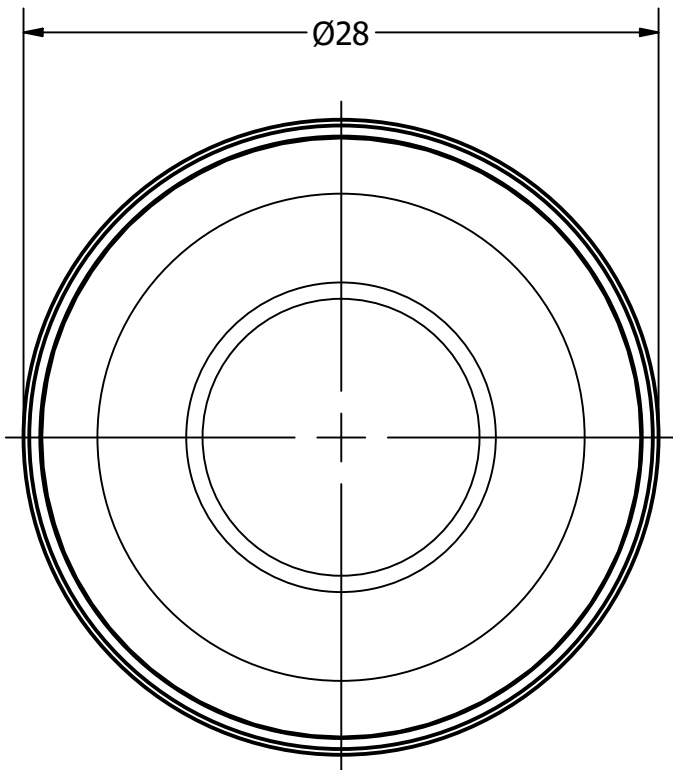

Side View

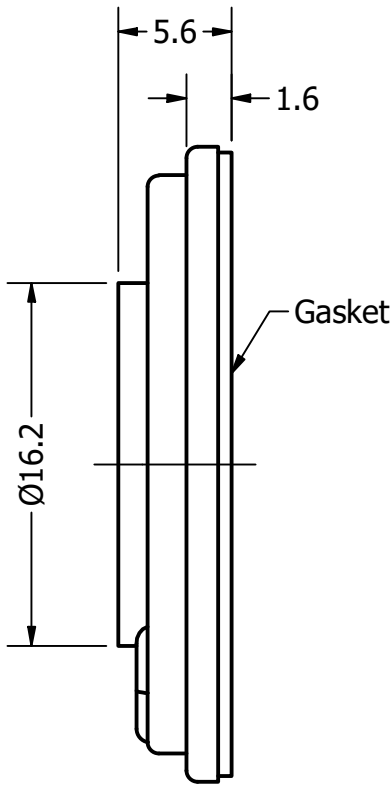

Bottom View

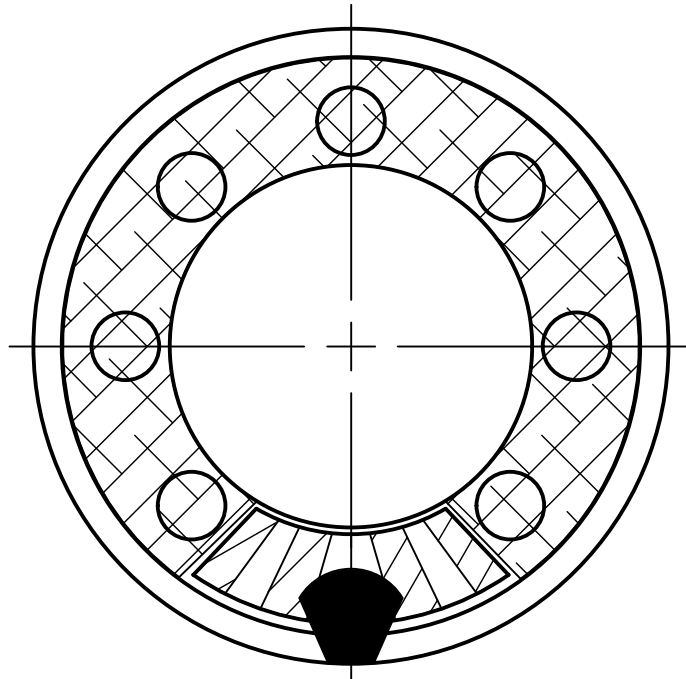

Items	Specifications	Conditions				
Sound Pressure Level	92	dB (@ 10cm)				
Resonant Frequency	550	Hz				
Frequency Range	550 ~ 9,000	Hz				
Nominal Power	1.5	W				
Max. Power	3.0	W				
Impedance	8	Ω				
Cone Material	Paper					
Mount Type	Flush Mount					
Storage Temperature	-30 ~ +60	$^{\circ}\text{C}$				
Operating Temperature	-20 ~ +60	$^{\circ}\text{C}$				
Weight	8.7	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	2/5/2014	J.S.
1	Revised cone material to paper, updated to new template	4/5/2021	J.S.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	