



## Product Line

Single Pair Ethernet &gt;

ZConnect &gt;

Ceres &gt;

Accessory

Large Size

Macro Size

Middle Size

Mini Size

Others (GBO)

Others (MAB)

Others (PLD)

Standard Size

X-Lok &gt;

M Series &gt;

FLOS &amp; FLOS+ &gt;

Power &gt;

RBL &gt;

HS-Lok &gt;

IEC60529

ABOUT AMPHENOL LTW

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

Heavy Duty Shielded &gt;

RJ &gt;

USB &gt;

SSL &gt;

HDMI &gt;

DVI &gt;

Fiber Optic &gt;

RF &gt;

Cable Joiner &gt;

Cable Gland &gt;

Pressure Relief Vent &gt;

LED Light Guide &gt;

D-Sub &gt;


**ABD-08BFFM-LL7A01**

Operating Temperature: -20°C ~ +80°C

Transmission Speed: N/A

Shielded: Plastic, Non-shielded

Jacket Material: PVC

Certificate: N/A

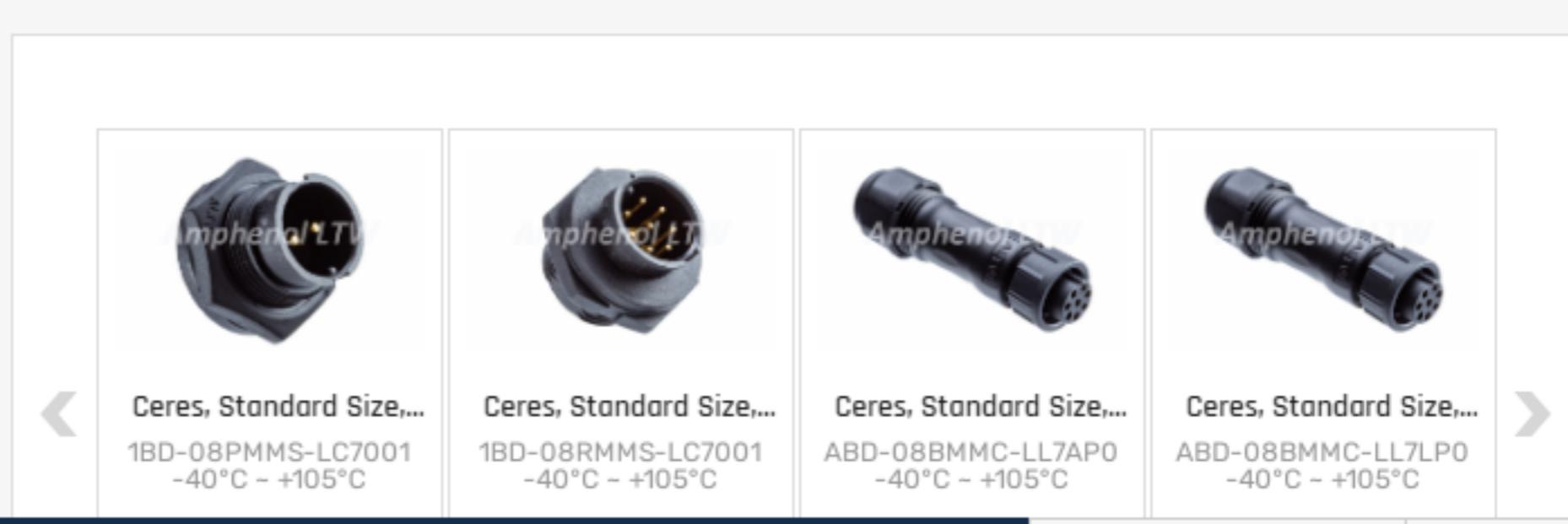
You must login first for view the price

Quantity - 1 +


 Can't find? [Customize your part](#)

## Mating Pair & Accessories

Connector Type


**Specifications**

Download / CAD

Nominal Current

Connector Type

5A

Overmolded

Shielded

No. of Contacts

Plastic, Non-shielded

08

Connector Gender

Backshell

Female

Straight

Mating Style

IP Rating

2 Points Lock

IPX7

Assembly Style

N/A

## People Also Bought

