



# Sta-Kon®

**Ring Terminal**  
**T&B Catalog Number:**


**UPC Number:**  
**Status:**  
**Description:**

RF4-516  
 78621087214  
 Active

Nylon Insulated Large Ring Terminal, Length 1.84 Inches, Width .62 Inches, Maximum Insulation .510, Bolt Hole 5/16 Inch, Wire Range 4, Color Yellow, Copper, Tin Plated

**Features**

Funneled Barrel Entry, Deep Internal Serrations, Brazed or overlapping seams.

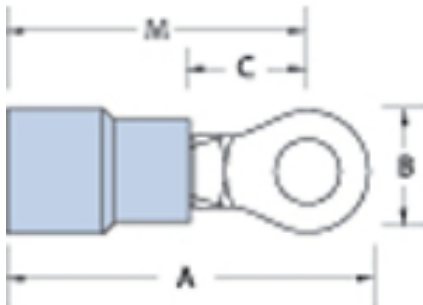

**General**

Insulation Type	Insulated Nylon
Terminal Series	RF
Material	Copper
Finish	Electro -Tin Plated
Color	Yellow
Wire Range	4
Stud Size	5/16

**Dimension Information**

Maximum Insulation (inches)	.510
Stock Thickness	.04
A (inches)	1.84
B (inches)	.62
C (inches)	.35
M (inches)	1.53

**Specifications**

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2

**Tooling**

Tool Charts	Available on Website
Application Tools	TBM6, TBM6S, ERG4007
Recommended Tool	TBM6S

**Packaging**

T&B Order Multiple	15
T&B Inner Pack	15
Package in Units	150
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	2.31 lbs. per 100
Alternate Package Qty	RF727

**Application Support**

T&B Sales Drawings	wsd-000208
Overview	Available on Website
Wire Guide Tables	Available on Website

## Notes

Not available on Mylar Tape.

## Certifications

RoHS Compliance

Yes

## Certifications



File Nbr:

E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)