


THESE DRAWINGS ARE THE PROPERTY OF QUALTEK ELECTRONICS AND NOT TO BE REPRODUCED FOR OR COMMUNICATED TO A THIRD PARTY WITHOUT THE EXPRESS WRITTEN PERMISSION OF AN OFFICER OF QUALTEK ELECTRONICS.

REVISION			
REV.	DESCRIPTION	DATE	APPROVED
B	RoHS Compliancy	06-01-06	DP
C	Updated Specifications	12-20-07	DP
D	Updated Approvals	03-03-16	LY

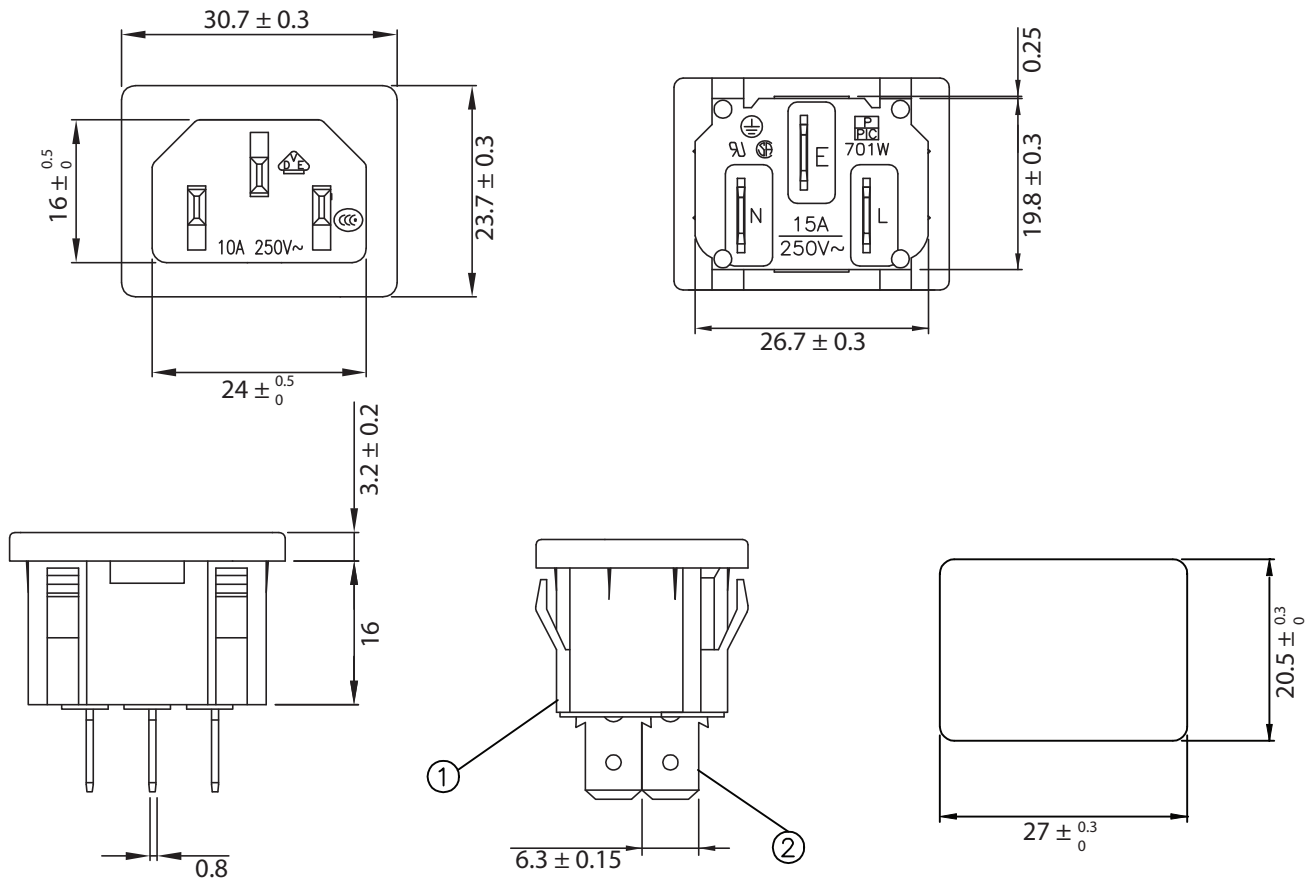

CONTROLLED

NOTES:

RATING:

UL, CSA: 15A 250V AC
VDE, CCC: 10A 250V AC
INSULATION RESISTANCE: OVER 100M OHM 500V DC
DIELECTRIC RESISTANCE: 2000V AC ONE MINUTE
PANEL THICKNESS: 0.8mm ~ 1.5mm
APPROVALS: UL, CSA, VDE, CCC
RoHS COMPLIANT

2	Contact PIN Brass Strip Tin-Plated	3
1	Body Insulator Nylon Black Color	1
Qualtek Electronics Corp. PPC DIVISION		
Part Number: 701W-X2/04		RoHS Compliant
Description: AC RECEPTACLE		
Dim range (mm)	Tolerance +/- (mm)	
0-1	0.15	
1-6	0.20	
6-18	0.30	
18-50	0.50	
50-120	0.70	
120-250	0.90	
250-500	1.20	
Drawn / Date		UNIT: mm
B.Zhang 05-11-05		REV.D
Checked / Date		Approved / Date
05-11-05		JJH / 05-11-05