
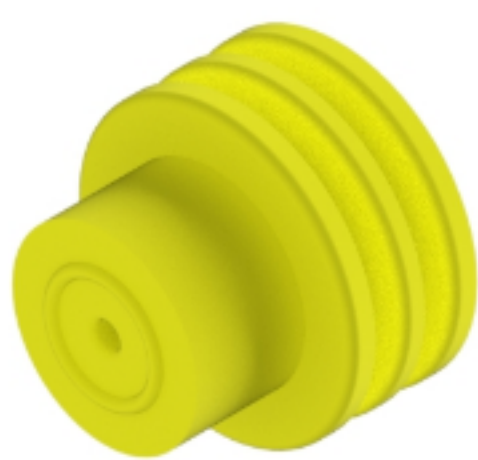



SEARCH KEYWORD, PART NUMBER 



Part Number: 15363779

SINGLE WIRE SEAL FITS TO 8.5 mm CAVITY

 [Share](#)  [Print](#) [Contact Us About This Item](#)

GET SAMPLES 






ATTRIBUTES DOCUMENTS ECAD

Attributes

Type	SINGLE WIRE SEAL	Hardness (Shore)	50
Outer Diameter (mm)	9	Contains Lubricant (Oil Content)	Low
Barehole Diameter (mm)	0.8	Restraint Ring	No
Length (mm)	7.8	Min. operating temperature	-40°C
Min Cable Outer Diameter (mm)	1.2	Max. operating temperature	+140°C
Max Cable Outer Diameter (mm)	2		
Color	YELLOW		

Other Products

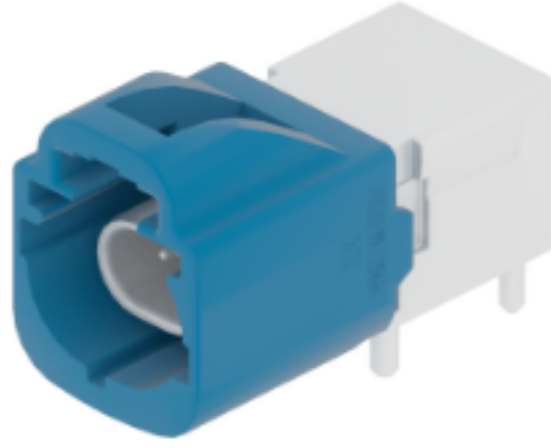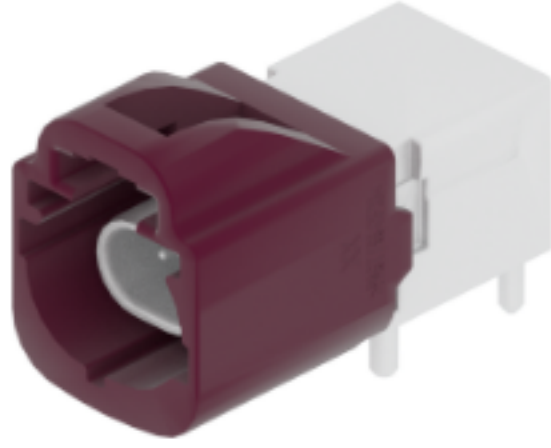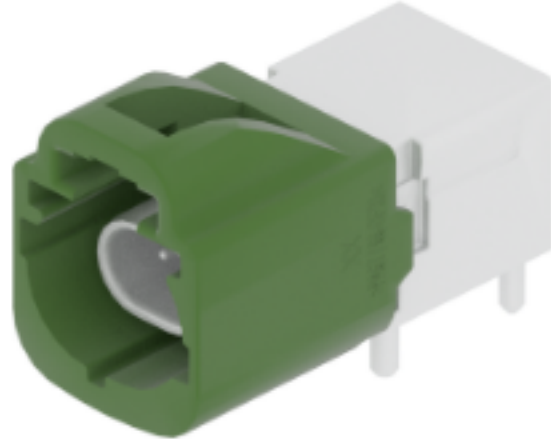

RESOURCE-CENTER-ITEM
COV CONN CLIP CDT BLACK


35829171
2 Way Male 0.5 Unsealed Green

35829170
2 Way Male 0.5 Unsealed Violet

35829169
2 Way Male 0.5 Unsealed Blue



Next Steps

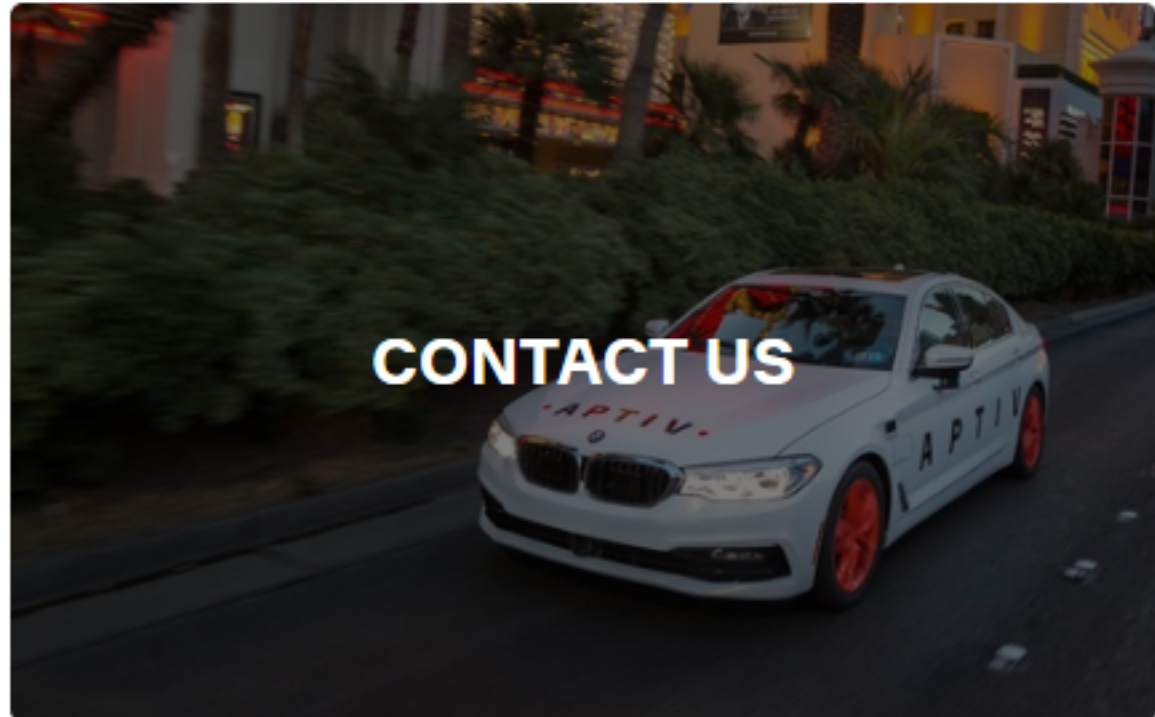

Keep pace with where mobility is going.

See what's next and get the latest updates.

SIGN UP TO GET UPDATES 

Don't worry. We won't flood your inbox or share your email.

INSIGHTS

EXPLORE ALL ARTICLES
CASE STUDIES
MOBILITY INSIDER
RESEARCH PUBLICATIONS
WHITE PAPERS

SOLUTIONS

Advanced Safety
Connected Services
Connection Systems
Connectivity and Security
Electrical Distribution Systems
Middleware & DevOps
Smart Vehicle Architecture
User Experience
Vehicle Electrification Systems
HellermannTyton
Intercable Automotive Solutions
Motional
Winchester Interconnect
Wind River

CATALOG

ABOUT

Our Mission
Our Businesses
Our Locations
Our Foundation
Sustainability
Suppliers

PRIVACY

Terms of Use
Cookie Policy

LEGAL & COMPLIANCE

CAREERS

INVESTORS
NEWSROOM
CONTACT