

BBPY00321611122Y00

Search by :

- Part Number
- Characteristics
- Cross reference




MP ?

For Power Line
Under 1 GHz

- Series Pdf
- ICP Report
- RoHSREACHCoC

Product detail		
L (mm) ±		3.20±0.20
W(mm) ±		1.60±0.20
T (mm) ±		1.10±0.20
Size Code (JIS/EIA)		3216/1206
RDC(Ω)Max		0.18
Rated Current(mA)		1000
Rated Current(mA)Max		1000
Impedance Ω(at 50MHz)		1200
Tolerance(±%)		25
Test Frequency		50 MHZ,200 mV

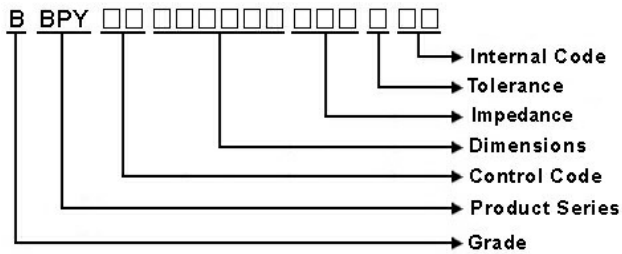

Products

- Power Inductor
- EMI-Noise Suppression
- RF-Signal Inductor
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

News

- Media Center
- New Products
- Events
- Product Notices

Contact Us



Copyrights © 2018. Chilisin. All rights reserved.