



TOP VIEW

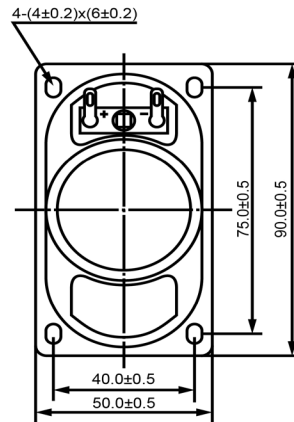

SIDE VIEW

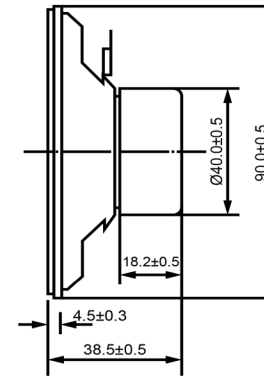

Specifications			Notes	Revision History						
Description	Value	Unit		Version	Description		Date	Approved		
Shape	Rectangle		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S		
Resonant Frequency	180	(Hz)								
Frequency Range	180 ~ 16,000	(Hz)								
SPL @ 10cm	85	(dBA)								
Impedance	8	(Ohm)								
Cone Material	Paper									
Nominal Power	3	(W)								
Max Power	5	(W)								
Mount Type	Frame									
Operating Temperature	-25 ~ +55	°C								
Storage Temperature	-25 ~ +55	°C								
Weight	172	(g)								
 DB UNLIMITED				Drawn by		Date	Checked by	Date	Approved by	Date
				A.B.		10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			Dynamic Speaker		SP900108-1					