



Connectors > Automotive Connectors: Car, Truck, Bus, & Off-Road > Automotive, Truck, Bus, & Off-Road Headers > SIGNAL HEADER

3POS,TAB 0.63X0.64,HEADER ASSY,BK



✓ ACTIVE

MQS

TE Part # **1563144-1**

TE Internal #: **1563144-1**

[All SIGNAL HEADER \(466\)](#)

Number of Positions : **3**

Centerline (Pitch) : **2.54 mm [.1 in]**

Sealable : **No**

Mounting Orientation : **Horizontal/90°**

Number of Rows : **1**

Add to List ▾



ORDER SAMPLES

[Compatible Parts & Tooling](#)



SHOP OUR DISTRIBUTORS

North America ▾

Request pricing, availability and customization options

CONTACT US



We are here to help!

Get in touch with our product experts.



CHAT WITH US



EMAIL US



CALL US

DOCUMENTS

FEATURES

PRODUCT COMPLIANCE

Product Description

TE offers an extensive header portfolio in all possible configurations to ensure signal transmission in automotive applications.

[View All SIGNAL HEADER \(466\)](#)

Product Drawings

3POS,TAB 0.63X0.64,HEADER ASSY,BK

[3POS,TAB 0.63X0.64,HEADER ASSY,BK](#) English

CAD Files

3D PDF

[3D_CVM_CVM_1563144-1_B.pdf](#) 3D

Customer View Model

[ENG_CVM_CVM_1563144-1_B.2d_dxf.zip](#)

English

[ENG_CVM_CVM_1563144-1_B.3d_igs.zip](#)

English

[ENG_CVM_CVM_1563144-1_B.3d_stp.zip](#)

English

Product Description

TE offers an extensive header portfolio in all possible configurations to ensure signal transmission in automotive applications.

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features Sealable : **No**
Connector & Contact Terminates To :
Printed Circuit Board
Hybrid Header : **No**
Shielded : **No**

Configuration Features Number of Positions : **3**
Number of Rows : **1**
Number of Sections : **1**
Number of Signal Positions :
3

Body Features Color : **Black**

Contact Features Tab Width : **.63 mm [.025 in]**
Tab Thickness : **.63 mm [.025 in]**
Interface Plating : **Tin (Sn)**

Termination Features Termination Method : **Through Hole - Solder**

Mechanical Attachment PCB Mount Retention Type :
Boardlock
PCB Mount Retention : **With**
Panel Mount Feature : **Without**
PCB Mount Alignment : **Without**
Mounting Orientation : **Horizontal/90°**
Locking Interface : **Without**

Housing Features Centerline (Pitch) : **2.54 mm [.1 in]**


Dimensions Width (in): **.736**
Length : **13.8 mm [.543 in]**

Operation/Application Circuit Application : **Signal**



Industry Standards	UL Flammability Rating : UL 94-HB
Packaging Features	Packaging Type : Tray
Statement of Compliance	Statement of Compliance pdf

Compatible Parts

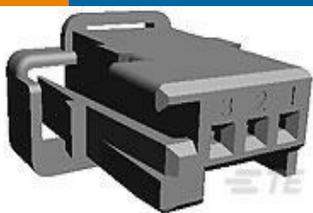

TE Part # 953697-1
**3W MQS RCPT HSG
 POSI MATE**

[View Product](#)


Also in the Series | MQS



**Automotive
 Connector Caps &
 Covers (138)**



**Automotive
 Connector EMC
 Shielding (2)**

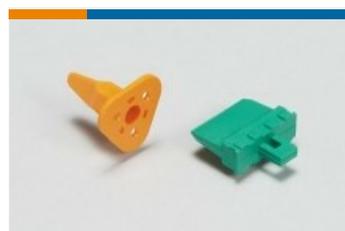

**Automotive
 Connector Locks &
 Position Assurance
 (27)**



**Automotive Seals &
 Cavity Plugs (34)**

Customers Also Bought



TE Part # 1633863-1
ANVIL, AMPLIVAR

TE Part # 1633863-2
ANVIL, AMPLIVAR

TE Part # 1-1633733-1
ANVIL, WIRE

TE Part # 1452480-9
**2 WAY JACK CONN.
8MM PITCH**

About TE Connectivity

For Partners

Customer Support

CALL US

LIVE CHAT

United States

Our Company

Events

TE News Center

Careers

Investors

Corporate Responsibility

Terms and Conditions of
Sale

Distributors

Suppliers

 Email or Call Us

 Find Authorized Distributors

 What's New on TE.com

 Product FAQs

Select Country & Language

United States (EN)

Germany (DE)

China (中文)

Japan (日本語)

Find Your Country/Region ▼

[Terms of Use](#) | [Privacy](#) | [Cookie Policy](#) | [Accessibility](#) | [Site Map](#)



© 2018 TE Connectivity. All Rights Reserved.