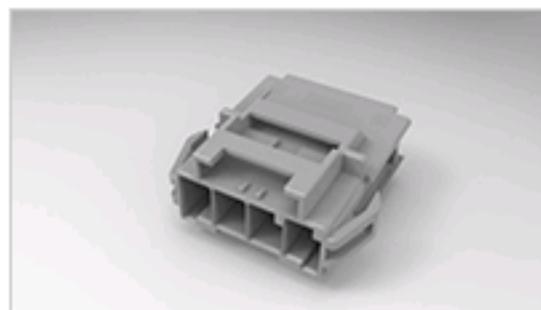


## 8-1971772-4 Product Details

[Share](#) [Print](#) [Email](#)

 Active  
[View 3D PDF](#)

### Power Triple Lock Connector System

1x4 cap housing panel mount Key D lgr

**8-1971772-4**

TE Internal Number: 8-1971772-4

[Product Highlights](#) [View All](#)

- Power Triple Lock Product Line
- Wire-to-Panel
- Applies To Panel
- Connector
- Connector Assembly

[Pricing & Availability](#)
[Request Sample](#)
[Add to My Part List](#)
[Buy Product through Distributor](#)
[Feedback](#)
[Documents](#)
[Features](#)
[Compliance](#)
**Please Note:**

Use the Product Drawing for all design activity

**Product Type Features**

Product Line	Power Triple Lock
Product Type	Connector
Connector Type	Connector Assembly

**Mechanical Attachment**

Mating Retention Type	Latch(ing)
Panel Mount Retention	With
Mount	Panel
Panel Mount Retention Type	Mounting Ear(s)

**Electrical Characteristics**

Operating Voltage (VAC)	600
Operating Voltage (VDC)	600

**Dimensions**

Panel Thickness (mm [in])	1.00 – 2.00 [0.039 – 0.079]
---------------------------	-----------------------------

**Body Features**

Mating Retention	With
------------------	------

**Contact Features**

Contact Layout	In-Line
----------------	---------

**Housing Features**

Connector Style	Receptacle
Centerline (mm [in])	6.00 [0.236]
Housing Material	Nylon - GF
Housing Color	Light Gray

**Configuration Features**

Number of Positions 4

**Industry Standards**

RoHS/ELV Compliance RoHS compliant, ELV compliant

Lead Free Solder Processes Not reviewed for lead free solder process

RoHS/ELV Compliance History Always was RoHS compliant

UL Flammability Rating UL 94V-0

**Identification Marking**

Keying D

**Environmental**

Operating Temperature (°C [°F]) -55 – +150 [-67 – +302]

Halogen Free Yes

**Conditions for Usage**

Applies To Panel

Glow Wire Rating High Temperature Part - Not Glow Wire

**Operation/Application**

Application Use Wire-to-Panel

Contact Transmits (Typical Application) Power

**Other**

Brand TE Connectivity

**Related Products**

Not quite the product you're looking for?

[Find Similar Products](#)
[View Part in Product Feature Selector](#)
[Check for Tooling](#)
**Corporate Information**

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

**Quick Links**

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

**Customer Support**

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

**Keep Me Informed**
