


- Quick Links
- Cross reference
- RoHS/LF P/N Search
- Industry Standards
- Alphabetical List
- Documentation
- 3D model search
- Customer drawing search
- Multi Selection Search
- Search by category

Start > Search=10120773-101LF* > 10120773-101LF

10120773-101LF

10120773-101LF - AIRMAX VSe®: 5-Pair, 150 -position, 2 mm pitch, 10 column, Vertical Receptacle

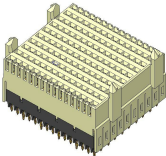

Customer drawing

Product Environmental Compliance Report

ACTIVE

RoHS Compliant

Distributor Stock

Print Datasheet

FCI Brings You More

Contact our sales/technical support

Sample request

- Specifications
- Download document
- Mating Half

Dimensional General Physical

Dimensional	
Pitch (Slot - min)	27 mm
Stack Height	12.5 mm
Spacing (Column)	2 mm
General	
Number of contacts	150
Orientation	Vertical
Product Series	AirMax VSe
Style	Signal Receptacle 2 mm
Termination Style	Press-Fit
Number of columns	10
Number of differential pairs (per column)	5
Physical	
Material (Contact)	Copper Alloy
Material (Housing)	Hi-Temp Thermo Plastic
Plating (Contact)	Au over Ni

Disclaimer : The information above is for reference only. For more technical details, refer to product specification and application specification.