


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:	<u>0352720210</u>
Status:	Active
Description:	6.00mm Tab Wire-to-Wire Plug Housing, Secondary Lock, 2 Circuits

Documents:

[Drawing \(PDF\)](#)
[Packaging Specification PK-35272-002 \(PDF\)](#)
[Product Specification PS-35270-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

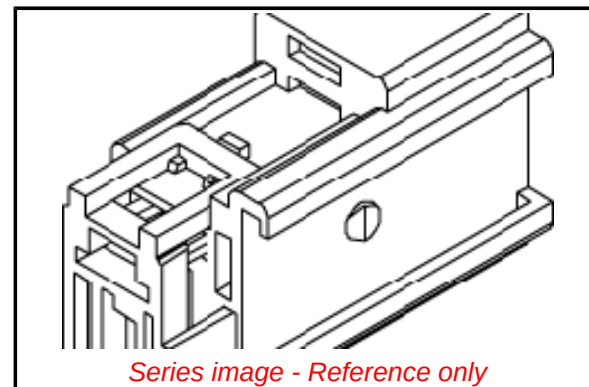

General

Product Family	Crimp Housings
Series	<u>35272</u>
Application	Power, Wire-to-Wire
Comments	Polarized to Mating Part
Product Name	N/A
UPC	756054264331

Physical

Circuits (maximum)	2
Color - Resin	Natural
Gender	Male
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	4.891/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	6.00mm
Pitch - Termination Interface	9.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +80°C

Electrical

Current - Maximum per Contact 6.0A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35272-002
Product Specification	PS-35270-001
Sales Drawing	SD-35272-0210

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Contains SVHC(2014
December 17): No

Halogen-Free

Status

Not Relevant

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Not Relevant
ELV	Compliant

Search Parts in this Series

35272 Series

Mates With

35270 Wire-to-Wire Receptacle Housing

Use With

35725 Slip-in Wire-to-Wire Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION