


Part Number : [354648000](#)
Product Description : Positive Terminal for PT Bulb
Socket, AVSS 0.50~0.85mm²
Series Number : 35464
Status : Active
Product Category : Crimp Terminals

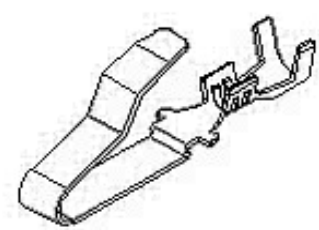

Documents and Resources

Drawings

[354648000_sd.pdf](#)

Specifications

[PK-35464-8000-001.pdf](#)

[PK-35903-001-001.pdf](#)

Tooling Specifications

[CS-35464-8000-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Crimp Terminals
Series	35464
Description	Positive Terminal for PT Bulb Socket, AVSS 0.50~0.85mm ²
Application	Power
Product Name	PT Bulb Socket
UPC	800754777261

Physical

Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Unplated
Net Weight	0.720/g
Packaging Type	Reel
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	1.60-2.30mm
Wire Size (AWG)	N/A
Wire Size mm ²	AVS 0.50-0.85

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Mates With / Use With

Use with Part(s)

Description	Part Number
PT Bulb Sockets	<u>35842</u>
PT Bulb Socket Sealed Single Housing Assemblies	<u>35843</u>

Application Tooling

Global

Description	Part Number
Extraction Tool for MX150L, MX150, PT Bulb Socket, iGrid, SPOX, and Wire-to-Motor Terminals	<u>638131500</u>
Hand Crimp Tool for Bulb Socket Positive Terminal	<u>638195000</u>

This document was generated on Apr 15, 2026