
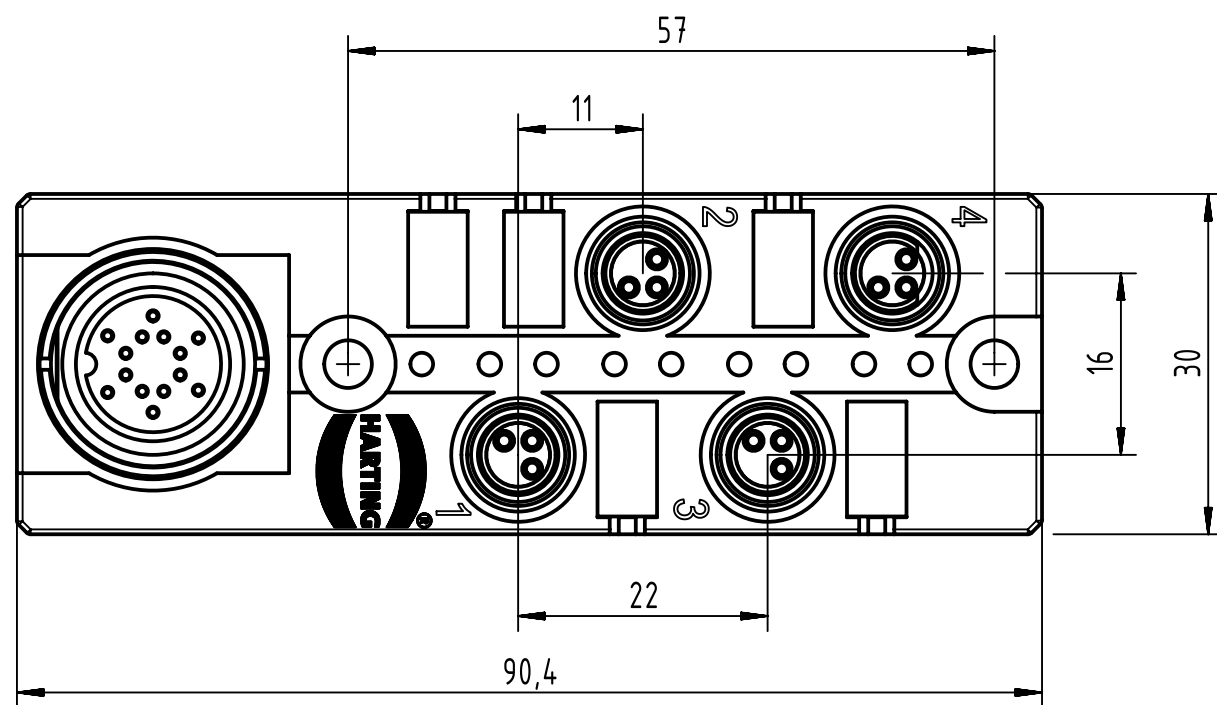



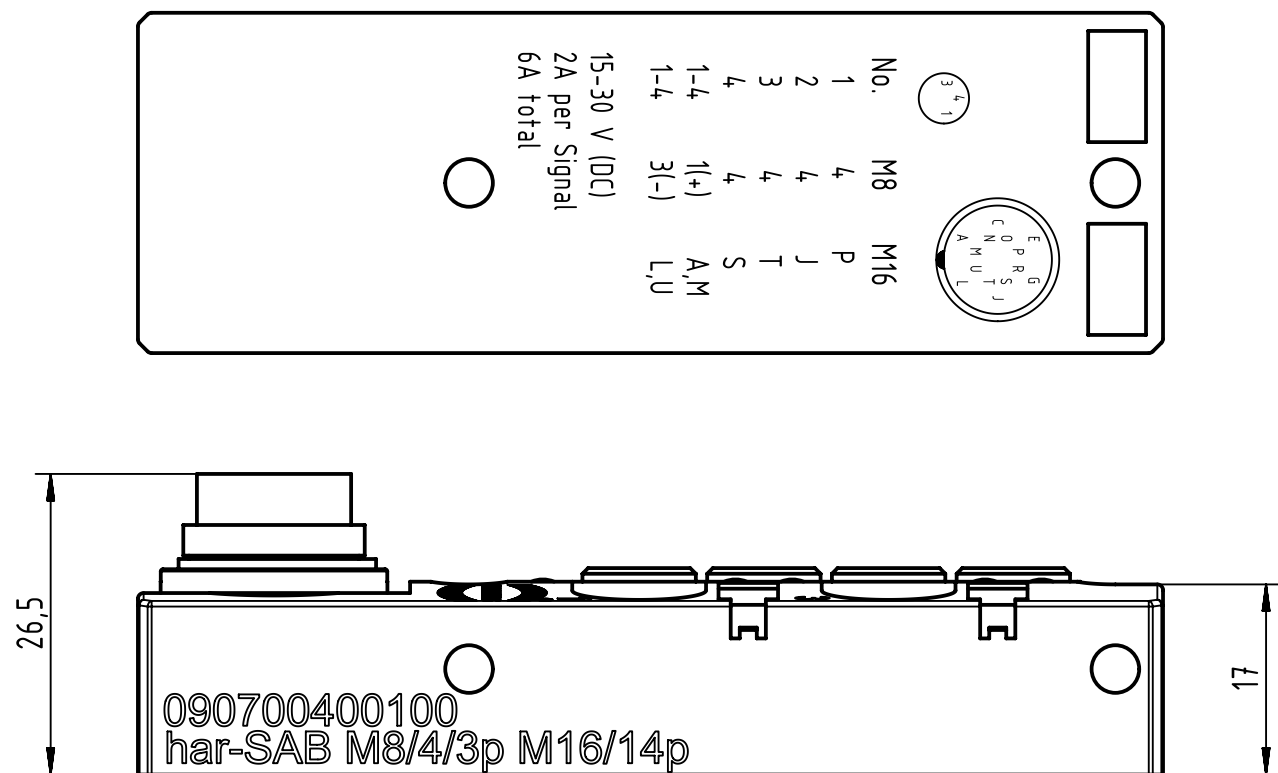


Electrical data:

- Rated voltage: 15-30V DC
- Nominal: 2 A per Contact
- Current: 6 A max total

- Protection level: IP 67
- Temperature range: -20°C...+80°C

Loading plan

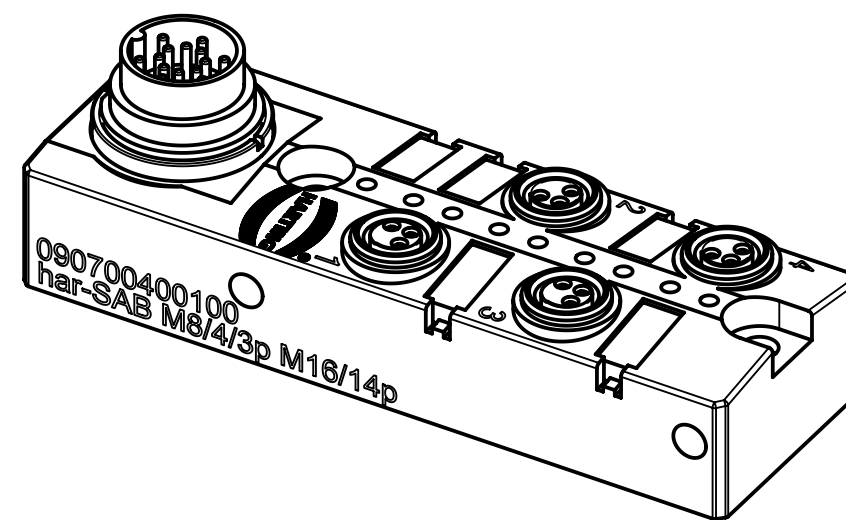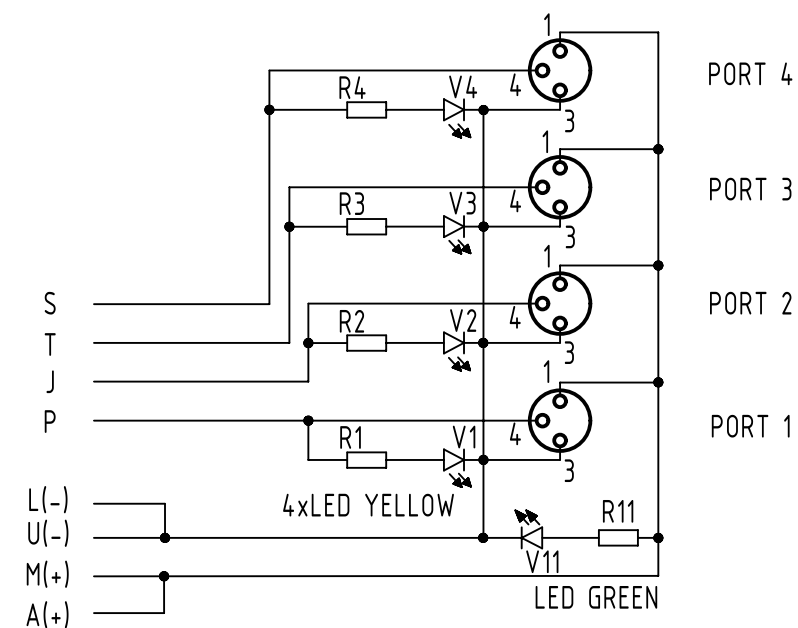

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by		Inspected by		Standardisation		Date	
Department HCS - RO		MUNTEANV		POPESCU		AVRAM		2017-04-24	
HARTING Customised Solutions		Title		har-SAB M8/4/3p M16/14p		Doc-Key / ECM-Nr.		100689722/UGD/000/C	
D-32427 Minden		Type		TB		Number		090700400100	
								Rev. C	
								Page 1/1	