


# OA4715 'Challenger Series'



AC Fans - 115, 230V  
120mm x 38.5mm (4.72" x 1.52")

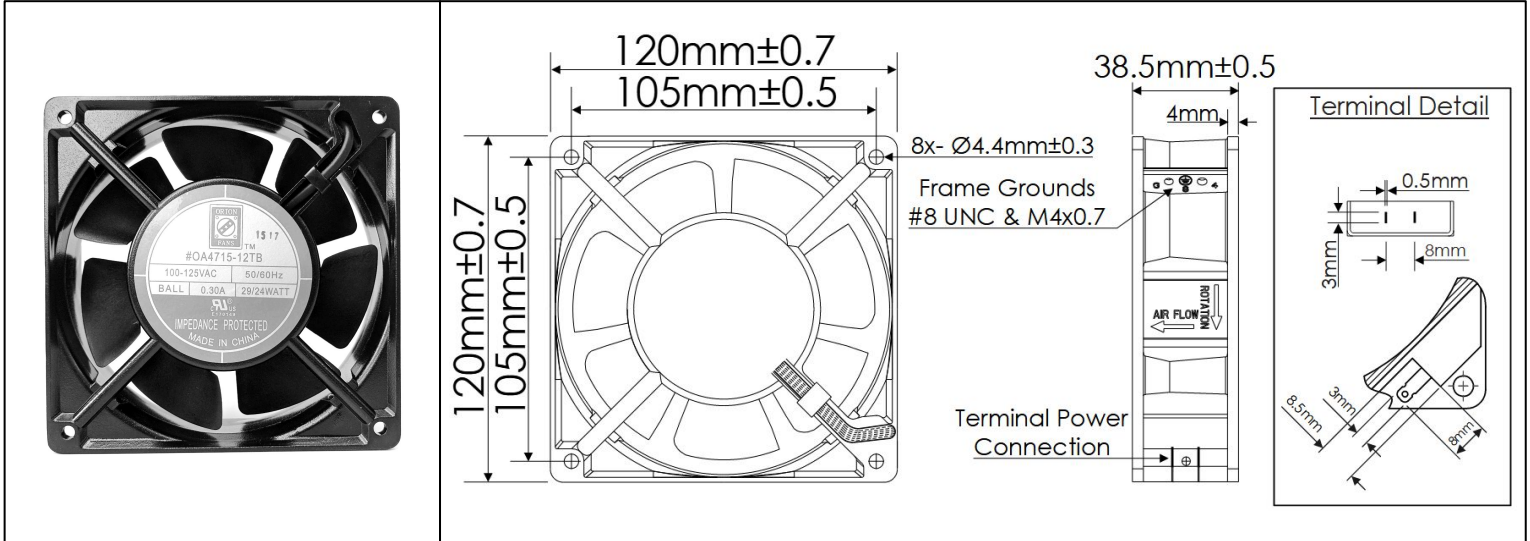

<b>Frame</b>	Die Cast Aluminum, Black	<b>Operating Temperature</b> -40°C ~ +70°C  <b>Storage Temperature</b> -40°C ~ +80°C  <b>Life Expectancy</b> 50,000 Hours (L10 at 25°C)  Weight: 1.11 lbs.
<b>Impeller</b>	PBT, UL94 V-0 Plastic	
<b>Connection</b>	2x Terminals	
<b>Motor</b>	AC Shaded Pole, Impedance Protected	
<b>Bearing System</b>	Dual Ball Bearings	
<b>Dielectric Strength</b>	1500VAC/min, <5mA	
<b>Insulation Resistance</b>	≥10MΩ @ 500 VDC	

Part Number	Rated Voltage (Volts AC)	Frequency (Hertz)	Rated Input (Watts)	Rated Current (Amps)	Rated Speed (RPM)	Max Airflow (CFM)	Noise Level (dBA)	Max Static Pressure ("H <sub>2</sub> O)
OA4715-12TB	115	50 / 60	29 / 24	0.30	2575 / 2980	96.7 / 110	40.4 / 44.2	0.29 / 0.37
OA4715-23TB	230	50 / 60	28 / 24	0.20	2575 / 2980	96.7 / 110	40.4 / 44.2	0.29 / 0.37