


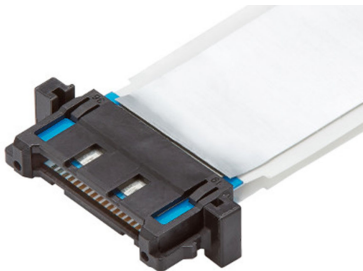


Part Number : 2051950361
Product Description : Easy-On FFC/FPC Connector, 0.50mm Pitch, FV2R Series, Plug, 250.00mm Shielded FFC, Vertical, 7.10mm Mated Height, 36 Circuits
Series Number : 205195
Status : Obsolete
Product Category : FFC / FPC Connectors



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Obsolete
--------	----------

Category	FFC / FPC Connectors
Series	205195
Description	Easy-On FFC/FPC Connector, 0.50mm Pitch, FV2R Series, Plug, 250.00mm Shielded FFC, Vertical, 7.10mm Mated Height, 36 Circuits
Series Name	FV2R
Product Name	Easy-On
UPC	193264136551

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

Physical

Actuator Type	Flexi-Latch
Circuits (Loaded)	36
Circuits (maximum)	36
Color - Resin	Black
Contact Position	Dual
Durability (mating cycles max)	20
Mated Height	7.10mm
Material - Resin	Polyester
Net Weight	5246.800/mg
Orientation	Vertical
Packaging Type	Bag
PCB Mounting	N/A
PCB Retention	N/A
Pitch - Mating Interface	0.50mm
Polarized to PCB	N/A
Stackable	No
Temperature Range - Operating	-20° to +85°C
Wire/Cable Type	FFC/FPC