


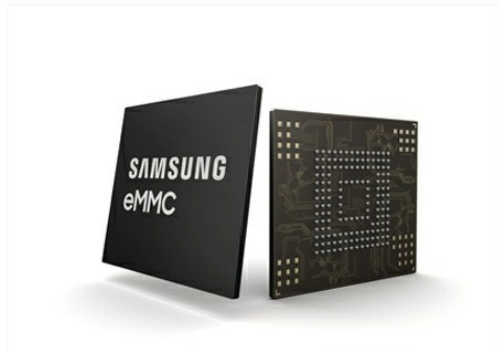

eMMC

KLM8G1GESD-B03P



OVERVIEW

SPECIFICATIONS

RELATED RESOURCES

RELATED INSIGHTS

Definitive Performance for Mobile Storage

With superior power efficiency and noticeably fast speed, Samsung's eMMC is the definitive choice for flash storage to develop slim mobile design.

- Consistent Optimal Speed
- High Performance at Low Power
- Extensive Lineup, Quick Response

Specifications

Version	eMMC 5.0	Density	8GB
Voltage	1.8 / 3.3 V	Interface	HS400
Package Size	11.5 x 13 x 0.8 mm	Temp.	-40 ~ 85 °C
Product Status	Mass Production		

[SEE ALL](#)

Related Resources



Samsung Memory
Solutions for Auto
motive



Samsung eMMC

Related Insights



Samsung Memory Solutions for Automotive

Reliable memory solutions for next level business and driving experience

[LEARN MORE >](#)



Automotive Driven by Small Packages Under the Hood

Discover Samsung's semiconductor solutions that are used in a wide array of automotive applications.

[LEARN MORE >](#)



All product specifications reflect internal test results and are subject to variations by user's system configuration. All product images shown are for illustration purposes only and may not be an exact representation of the product. Samsung reserves the right to change product images and specifications at any time without notice.

Insights

Product Finder

Technical Resources

TCO Calculator

PRODUCTS

DRAM

SSD

eSTORAGE

MCP

SOLUTIONS

APPLICATIONS

Global Sites

Samsung Business [↗](#)

Exynos [↗](#)

LED [↗](#)

Follow us



