


UC-EM (20X7) TQ - Snap-in markers



0825500

<https://www.phoenixcontact.com/us/products/0825500>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

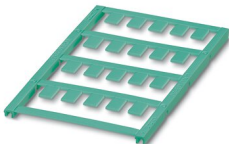

Snap-in markers, Sheet, turquoise, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: snapped, lettering field size: 20 x 7 mm, Number of individual labels: 20

Your advantages

- The markers, which are supplied in uniform sheets, can be labeled quickly and easily using the BLUEMARK LED
- The UC-EM ... UniCard labeling range includes markers for devices and switching devices from a wide range of manufacturers
- The format automatically ensures printing with a high degree of positioning accuracy
- The wide temperature range means that the labels can be used in control cabinets as well as the field
- The sheets provide space for including function texts

Commercial Data

Item number	0825500
Packing unit	1 pc
Minimum order quantity	10 pc
Sales Key	BG10
Product Key	BG2417
Catalog Page	Page 304 (C-3-2019)
GTIN	4046356364324
Weight per Piece (including packing)	8.78 g
Weight per Piece (excluding packing)	7.4 g
Customs tariff number	39269097
Country of origin	PL

UC-EM (20X7) TQ - Snap-in markers



0825500

<https://www.phoenixcontact.com/us/products/0825500>

Technical Data

Product properties

Product type	Device marking
Marking	
Number of individual labels	20
Number of individual labels per row	5
Marking technology	
Device	5147999 BLUEMARK CLED
Printability	UV LED technology

Mounting

Mounting type	snapped
---------------	---------

Material specifications

RoHS compliant	yes
Color	turquoise
Material	PA
Flammability rating according to UL 94	V2
Temperature index of insulation material (DIN EN 60216-1 (VDE 0304-21))	120 °C
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1 - HL 2
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1 - HL 2
Fire protection for rail vehicles (DIN EN 45545-2) R24	HL 1 - HL 2
Components	free from silicone and halogen

Environmental and real-life conditions

Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

UV resistance

Specification	ISO 4892-2:2013-03 (following)
Result	Test passed
Test duration	96 h

Wipe resistance of inscriptions

Specification	DIN EN 61010-1 (VDE 0411-1):2011-07
	DIN EN 62208 (VDE 0660-511):2012-06 (in parts)

Testing in a condensation changing climate in the presence of sulfur dioxide

Specification	DIN 50018:2013-05
Result	Test passed
Climate level	AHT 1.0 S
Cycles	2

UC-EM (20X7) TQ - Snap-in markers



0825500

<https://www.phoenixcontact.com/us/products/0825500>

Salt spray test

Specification	DIN EN 60068-2-11:2000-02
Result	Test passed

Ambient conditions

Ambient temperature (operation)	-40 °C ... 120 °C
Recommended storage conditions	23 °C/50 % relative humidity. Storage in a dry and dark place in the original packaging is recommended.
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %

Dimensions

Width	20 mm
Length	7 mm

Standards and regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



Classifications

ECLASS

ECLASS-11.0	27281103
ECLASS-12.0	27281103
ECLASS-13.0	27281103

ETIM

ETIM 8.0	EC001288
----------	----------

UNSPSC

UNSPSC 21.0	39131500
-------------	----------

UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



Accessories

BLUEMARK ID - Printer

1003334

<https://www.phoenixcontact.com/us/products/1003334>



Monochrome printer with UV LED technology, with integrated "MARKING system app" marking software on board. 7" touch color display for printing plastic tags in UC, UCT, US, and UM format, as well as metal plates.

BLUEMARK ID COLOR - Printer

1002329

<https://www.phoenixcontact.com/us/products/1002329>



CMYK multicolor printer with UV LED technology, with integrated "MARKING system app" marking software on board, 7" touch color display for printing plastic tags in UC, UCT, US, and UM format, as well as metal plates.

UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



BLUEMARK CLED - Printer

5147999

<https://www.phoenixcontact.com/us/products/5147999>

 


Printers with LED-UV technology for printing plastic labels in UniCard format.

PLOTMARK - Marking plotter

0804499

<https://www.phoenixcontact.com/us/products/0804499>



Marking plotter for the entire portfolio of UC marking materials and materials in sheet and strip format.

UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



BM ID-CLEANING CARTR. - Cleaning cartridge

1044350

<https://www.phoenixcontact.com/us/products/1044350>

Replacement cleaning cartridge



BLUEMARK CLED-FLUID-CARTR. - Ink cartridge

5146662

<https://www.phoenixcontact.com/us/products/5146662>

Cartridge, for replacement, 20 ml UV color, black, including cleaning cartridge



UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



BLUEMARK FLUID-CARTRIDGE - Ink cartridge

5147421

<https://www.phoenixcontact.com/us/products/5147421>

Cartridge, for replacement, 28 ml UV color, black including cleaning cartridge



CMS-DISPOSABLE-PEN 0,25 TR - Marker pen

5146685

<https://www.phoenixcontact.com/us/products/5146685>

Disposable pen, incl. adapter, integrated ink cartridge and pen station, writing thickness: 0.25 mm



UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



CMS-DISPOSABLE-PEN 0,35 TR - Marker pen

5146686

<https://www.phoenixcontact.com/us/products/5146686>

Disposable pen, incl. adapter, integrated ink cartridge and pen station, writing thickness: 0.35 mm



CMS-PEN 0,25 - Marker pen

5067815

<https://www.phoenixcontact.com/us/products/5067815>

Marker pen, incl. adapter, ink tank and reservoir, 0.25 mm nib



UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



CMS-PEN 0,35 - Marker pen

5067828

<https://www.phoenixcontact.com/us/products/5067828>

Marker pen, incl. adapter, ink tank and reservoir, 0.35 mm nib



CMS-PEN 0,50 - Marker pen

5067831

<https://www.phoenixcontact.com/us/products/5067831>

Marker pen, incl. adapter, ink tank and reservoir, 0.5 mm nib



UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



CMS-INK-TR-C5 - Ink cartridge

5146684

<https://www.phoenixcontact.com/us/products/5146684>

Ink cartridge, special black ink, 5 cartridges of 1 ml each, for high demands



CMS-R-SET-TR - Cleaning set

5146751

<https://www.phoenixcontact.com/us/products/5146751>

Cleaning set, consisting of: 1x cleaning cup, 2x cleaning cartridges with 10 ml cleaning fluid each and 2x replacement sealing caps for the CMS-PEN ... and CMS-DISPOSABLE-PEN ...



UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



CMS-R-FLUID-TR-C2 - Cleaning cartridge

5146752

<https://www.phoenixcontact.com/us/products/5146752>



Cleaning cartridges with replacement sealing caps, 2 cartridges with 10 ml cleaning fluid each and 2 caps for the CMS-PEN ... and CMS-DISPOSABLE-PEN ...

CMS-R-FLUID-TR - Cleaning fluid

5146750

<https://www.phoenixcontact.com/us/products/5146750>



Cleaning fluid, 30 ml, for the CMS-PEN ... and CMS-DISPOSABLE-PEN ...

UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



P1 UC-MAG 6 - Magazine

5146121

<https://www.phoenixcontact.com/us/products/5146121>

Magazine, for CMS-P1-PLOTTER and PLOTMARK, for accommodating UC-EMP..., UC-EMLP...



BM ID-CARTR. BK - Ink cartridge

1044345

<https://www.phoenixcontact.com/us/products/1044345>

Replacement UV fluid, 23 ml, color: black



UC-EM (20X7) TQ - Snap-in markers

0825500

<https://www.phoenixcontact.com/us/products/0825500>



BM ID-CARTR. CY - Ink cartridge

1044346

<https://www.phoenixcontact.com/us/products/1044346>



Replacement UV fluid, 23 ml, color: cyan

BM ID-CARTR. YE - Ink cartridge

1044348

<https://www.phoenixcontact.com/us/products/1044348>



Replacement UV fluid, 23 ml, color: yellow

Phoenix Contact 2023 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com