


Product data sheet

Specifications

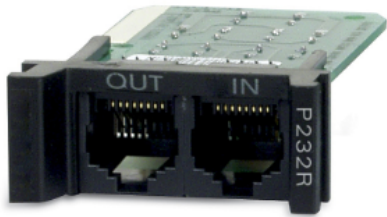

APC Surge Protection Module for RS232, Replaceable, 1U, for use with PRM4 or PRM24 Rackmount Chassis

P232R

⚠ Discontinued - Service only

⚠ Discontinued on: 21 September 2021

Overview

Lead time Usually in Stock

Main

Number of rack unit 0U

Provided equipment User manual

Physical

Colour Black

Height 4.4 cm

Width 1.9 cm

Depth 6.9 cm

Net weight 0.18 kg

Mounting preference No preference

Mounting mode Not rack-mountable

Output

Number of power socket outlets 1

Environmental

Ambient air temperature for operation -5...45 °C

Relative humidity 0...95 %

Operating altitude 0...10000 ft

Ambient air temperature for storage -5...45 °C

Storage Relative Humidity 0...95 %

Storage altitude 0.00...3048.00 m

Surge Protection and Filtering

Data line protected 1-8

Response time	1 ns common mode
Peak current	0.25 kA common mode 0.2 kA normal mode

Packing Units

Package 1 Weight	0.41 kg
Package 1 Height	9.9 cm
Package 1 width	3.3 cm
Package 1 Length	9.5 cm
SCC14	30731304203385
Number of Units in Package 2	96
Package 2 Weight	6.20 kg
Package 2 Height	206.38 mm
Package 2 width	412.75 mm
Package 2 Length	638.18 mm
Number of Units in Package 3	28

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Lead free	Yes
WEEE	The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins
Take-back	Take-back program available

Contractual warranty

Warranty	Limited Lifetime
----------	------------------