



Pushing Performance
Since 1945

Han LC-module-F

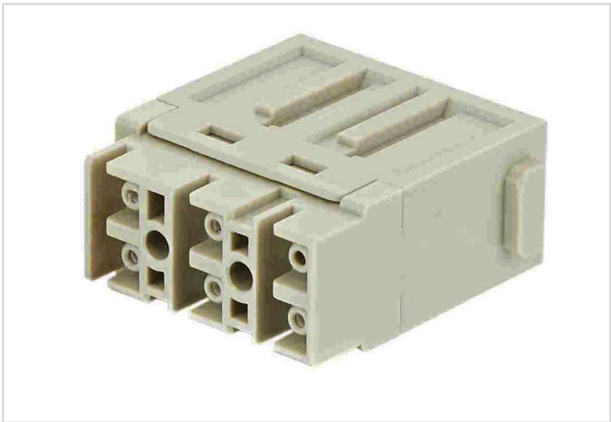


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 006 4711
Specification	Han LC-module-F
HARTING eCatalogue	https://harting.com/09140064711

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® LC module
Size of the module	Single module
Features	Suitable for LC contacts

Version

Gender	Female
Number of contacts	6
Details	Please order contacts separately.

Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

Commercial data

Packaging size	2
Net weight	1 g
Country of origin	Romania
European customs tariff number	85389099
GTIN	5713140020559
eCl@ss	27440219 Module for industrial connectors (FO)
ETIM	EC000438
UNSPSC 24.0	39121552