


USB-C Cable (M/M) - USB 2.0, 5A (100W) Rated, 6 ft. (1.83 m)

MODEL NUMBER: **U040-006-C-5A**

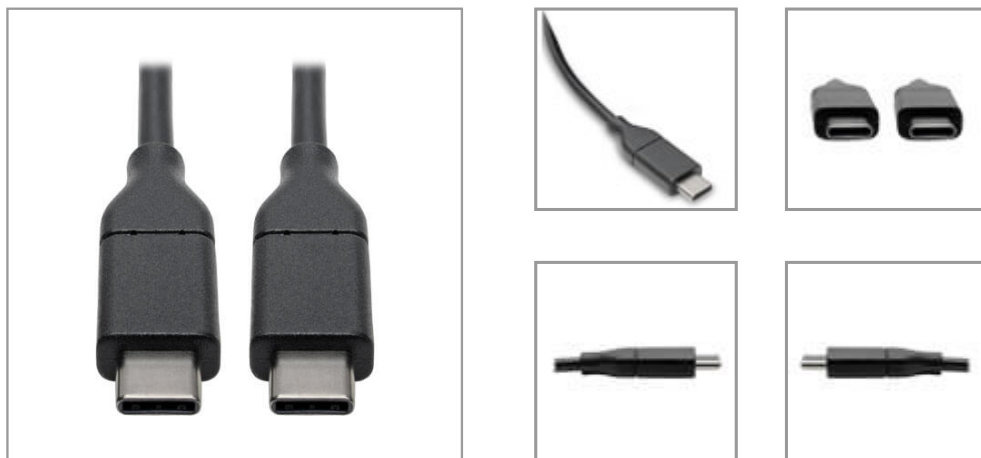

USB-C cable provides up to 20V 5A (100W) of power—more than enough to charge large-capacity mobile devices, such as the MacBook Pro®. Also connects smartphones, computers, wall chargers and other USB-C devices.

Features

Connects 2 USB-C Devices

- Power output up to 20V 5A (100W) for fast-charging large mobile devices, such as MacBook Pro
- Recommended for connecting smartphones, tablets, computers, wall chargers and other USB-C devices
- Supports USB 2.0 data transfer speeds up to 480 Mbps
- Backward compatible with previous USB generations

Reversible USB-C Male Connectors

- Fumble-free reversible plugs connect in either direction to ensure fast, easy connection every time

Premium Construction

- Molded connectors and gold-plated contacts for maximum conductivity and minimum data loss
- Foil and braid shielding delivers reliable, error-free signal quality and EMI/RFI protection

Specifications

OVERVIEW	
UPC Code	037332202871
Technology	USB 2.0 (High Speed)
USB Cable Type	Passive

Highlights

- Power output up to 5A for fast-charging large mobile devices
- Supports data transfer speeds up to 480 Mbps
- Reversible USB-C plugs on both ends for fumble-free connection
- Integral strain relief protects against stress and cracking
- Backward compatible with previous USB generations

System Requirements

- Devices with USB-C female connectors

Package Includes

- USB 2.0 Hi-Speed Cable with 5A Rating, USB-C to USB-C (M/M), 6 ft.

PHYSICAL	
Material of Construction	PVC
Cable Jacket Color	Black
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	4.0MM
Cable Length (ft.)	6
Cable Length (m)	1.83
Cable Length (in.)	72
Cable Length (cm)	182.9
Shipping Dimensions (hwd / in.)	0.50 x 7.00 x 9.00
Shipping Dimensions (hwd / cm)	1.27 x 17.78 x 22.86
Shipping Weight (lbs.)	0.30
Shipping Weight (kg)	0.14
ENVIRONMENTAL	
Operating Temperature Range	14 to 140 F (-10 to 60 C)
Storage Temperature Range	-4 to 185 F (-20 to 85 C)
Relative Humidity	10% to 85%, Non-Condensing
CONNECTIONS	
Side A - Connector 1	USB C (MALE)
Side B - Connector 1	USB C (MALE)
Connector Plating	Nickel
Contact Plating	Gold
FEATURES & SPECIFICATIONS	
USB Specification	USB 2.0 (up to 480 Mbps)
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	3-year limited warranty



1000 Eaton Boulevard
Cleveland, OH 44122
United States



© 2022 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.