

# Data Sheet

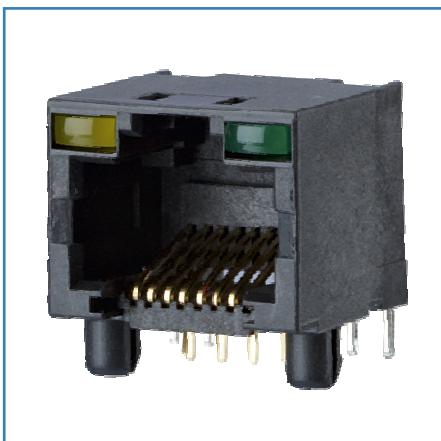
## AJT18L, 8P/8C

Page 1/3


 Part No.  
**AJT18L8813-010**

2013-12-23


### Illustrations



### Dimensions

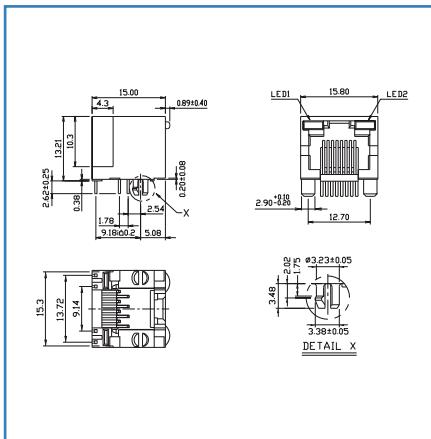

### PCB layout

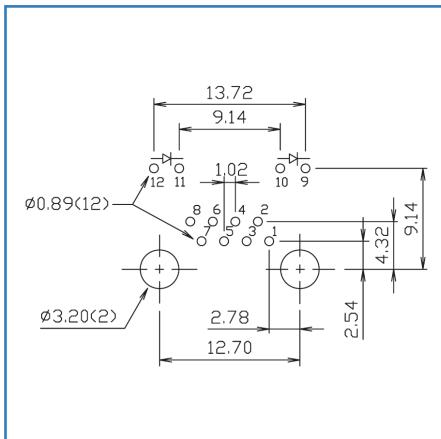

see enlarged drawings at the end of document

### Product Information

- PC board jack RJ45, unshielded
- single port, side entry, with 8 contacts
- solderable, color black
- L x W x H: 15.00 x 15.80 x 13.21 mm
- LED, yellow/green, top latch

### Technical Data

Soldering method	THT
Rated voltage max.	150 V
Rated Current	1 A
Contact resistance	50 mOhms
Insulation resistance	500 MOhms
Dielectrical Withstanding Voltage between contacts	1000 Vrms
between contacts and shield	1500 Vrms
Contact material	CuSn
Contact surface	gold flash 30 $\mu$ "
Mating force max.	22.55 N
Durability plug cycles	$\leq$ 750
Insulation material	PBT, UL94V-0
Insulation color	black
Operating Temperature	-40 °C to 85 °C
Type of protection	IP20
LED 1 / LED 2	yellow / green


 METZ CONNECT GmbH  
 Im Tal 2 | 78176 Blumberg | Germany | [www.metz-connect.com](http://www.metz-connect.com)  
 Phone +49 7702 533-0 | Fax +49 7702 533-433

 Montageanleitung / Mounting instruction siehe / see [www.metz-connect.com](http://www.metz-connect.com)

Members of METZ CONNECT



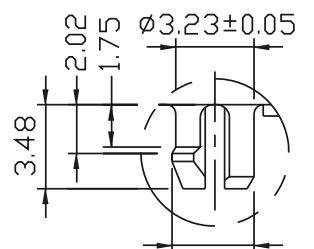
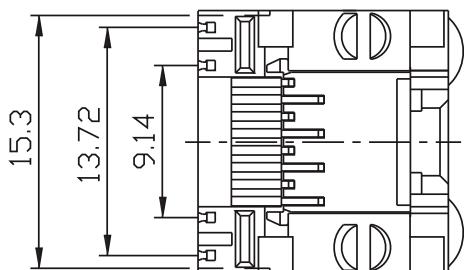
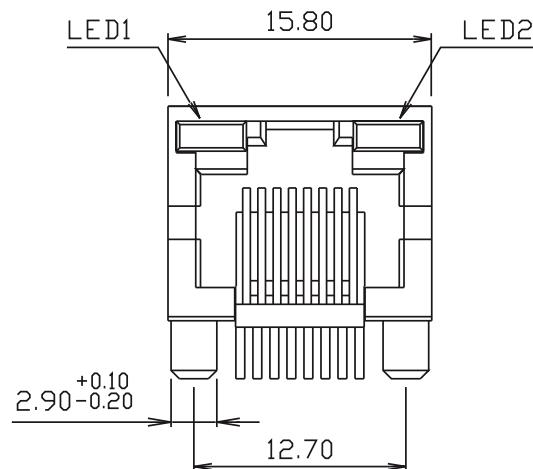
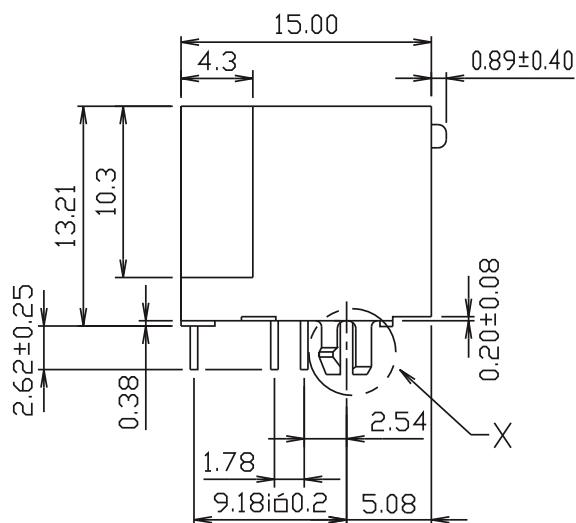
**Data Sheet**  
**AJT18L, 8P/8C**

Page 2/3

Part No.

**AJT18L8813-010**

2013-12-23

**Dimensions**

**DETAIL X**

 METZ CONNECT GmbH  
 Im Tal 2 | 78176 Blumberg | Germany | [www.metz-connect.com](http://www.metz-connect.com)

Phone +49 7702 533-0 | Fax +49 7702 533-433

 Montageanleitung / Mounting instruction siehe / see [www.metz-connect.com](http://www.metz-connect.com)
**Members of METZ CONNECT**


## Data Sheet

# AJT18L, 8P/8C

Page 3/3

**Part No.**

AJT18L8813-010

2013-12-23

## PCB layout

