


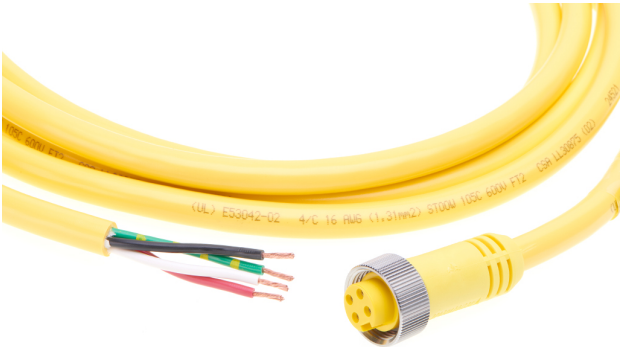

**Part Number :** [1300060738](#)  
**Product Description :** Mini-Change A-Size Single-Ended Cordset, 4 Poles, Female (Straight) to Pigtail, 16 AWG, Stainless Steel Coupling Nut, Yellow PVC Cable, 3.66m (12.0') Length  
**Series Number :** 130006  
**Status :** Active  
**Product Category :** Circular Industrial Cordsets  
**Engineering Number :** 104000A01F1201



Documents & Resources

**Drawings**  
[1300060738\\_sd.pdf](#)

Product Environment Compliance

Compliance

|                    |                                                                                                 |
|--------------------|-------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                                    |
| China RoHS         |            |
| EU ELV             | Not Relevant                                                                                    |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21                                                              |
| REACH SVHC         | Contains Lead; diphenyl(2,4,6-trimethylbenzoyl)phosphine oxide per D(2024)6225-DC (07 Nov 2024) |
| EU RoHS            | Compliant with Exemption 6(c) per EU 2015/863                                                   |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

|              |                                                                                                                                                              |
|--------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                                                       |
| Category     | Circular Industrial Cordsets                                                                                                                                 |
| Series       | 130006                                                                                                                                                       |
| Description  | Mini-Change A-Size Single-Ended Cordset, 4 Poles, Female (Straight) to Pigtail, 16 AWG, Stainless Steel Coupling Nut, Yellow PVC Cable, 3.66m (12.0') Length |
| IP Rating    | IP67                                                                                                                                                         |
| Product Name | Mini-Change                                                                                                                                                  |
| Type         | Single Ended                                                                                                                                                 |
| UPC          | 78678843088                                                                                                                                                  |

#### Agency

|     |         |
|-----|---------|
| CSA | LR6837  |
| UL  | E152210 |

#### Electrical

|                               |       |
|-------------------------------|-------|
| Current - Maximum per Contact | 10.0A |
| Voltage - Maximum             | 600V  |

#### Physical

|                      |                 |
|----------------------|-----------------|
| Cable Diameter       | 10.67mm (.420") |
| Cable Length         | 3.66m (12.0')   |
| Color - Cable Jacket | Yellow          |
| Connector End A      | Mini-Change     |
| Connector End B      | Pigtail         |
| Coupling Style       | Threaded        |
| Gender               | Female-Pigtail  |

|                               |                     |
|-------------------------------|---------------------|
| Keyway                        | Single              |
| LED Indicator                 | None                |
| Material - Cable Jacket       | PVC                 |
| Material - Connector Body     | TPE                 |
| Material - Contact            | Copper Alloy        |
| Material - Coupling Nut       | Stainless Steel     |
| Material - Plating Mating     | Gold                |
| Net Weight                    | 122.000/g           |
| Orientation                   | Straight to Pigtail |
| Poles                         | 4                   |
| Temperature Range - Operating | -20° to +105°C      |
| Wire/Cable Type               | STOOW               |
| Wire Size (AWG)               | 16                  |

---

This document was generated on Mar 09, 2025