


CD-HF 80X80 BU - Cable duct

3240601

<https://www.phoenixcontact.com/us/products/3240601>



Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

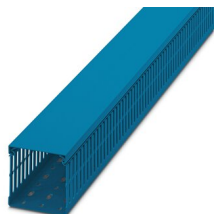

Cable duct for installation and mounting in control cabinets, blue, halogen-free, comprising upper part and mounting base, width: 80 mm, height: 80 mm, length: 2000 mm

Commercial Data

| | |
|--------------------------------------|---------------------|
| Item number | 3240601 |
| Packing unit | 1 pc |
| Minimum order quantity | 6 pc |
| Sales Key | BE74 |
| Product Key | BE7442 |
| Catalog Page | Page 579 (C-3-2019) |
| GTIN | 4046356630184 |
| Weight per Piece (including packing) | 1,466 g |
| Weight per Piece (excluding packing) | 1,466 g |
| Customs tariff number | 39259020 |
| Country of origin | DE |

CD-HF 80X80 BU - Cable duct

3240601

<https://www.phoenixcontact.com/us/products/3240601>



Technical Data


Product properties

| | |
|--------------|-------------|
| Product type | Wiring duct |
|--------------|-------------|

Connection data

| | |
|-----------------------|----------|
| Nominal cross section | 4412 mm² |
|-----------------------|----------|

Dimensions
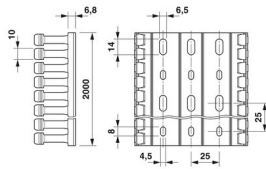
| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 80 mm |
| Height | 80 mm |
| Length | 2000 mm |

Material specifications

| | |
|--|--------------|
| Color | blue |
| Material | PC/ABS |
| Flammability rating according to UL 94 | V0 |
| Components | halogen-free |

Cable/line

| | |
|--------------|-----|
| Halogen-free | yes |
| Halogen-free | yes |

Environmental and real-life conditions

| | |
|---------------------------------|------------------|
| Ambient conditions | |
| Ambient temperature (operation) | -40 °C ... 90 °C |


CD-HF 80X80 BU - Cable duct

3240601

<https://www.phoenixcontact.com/us/products/3240601>



Drawings

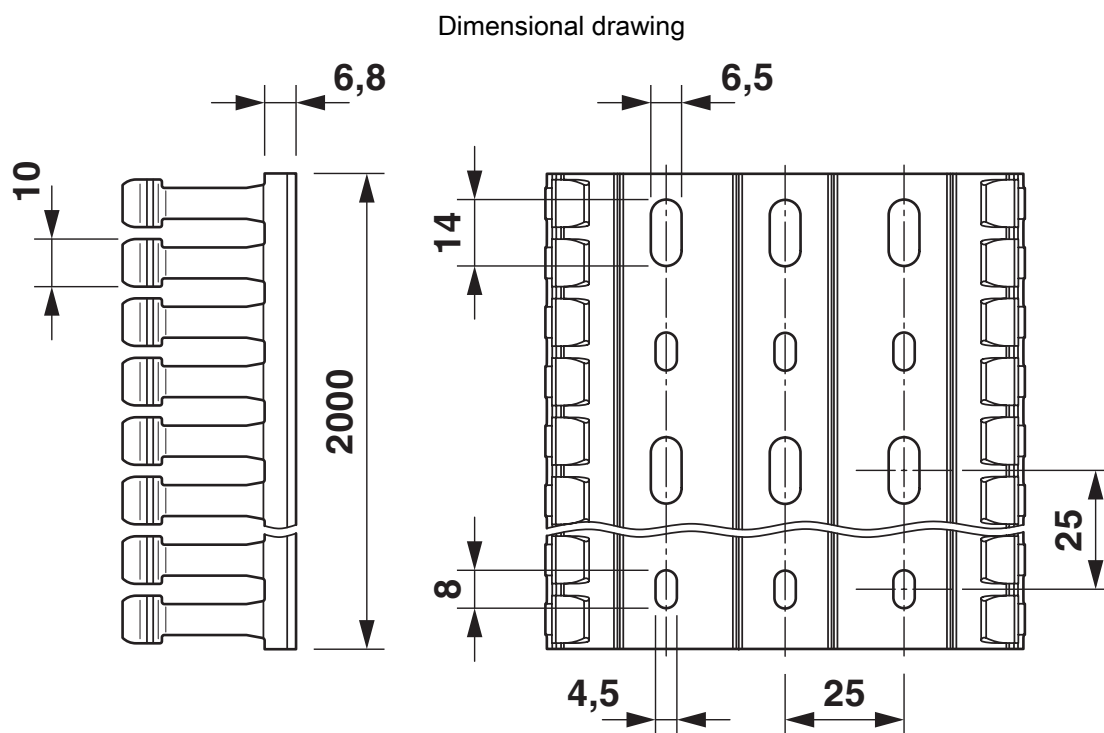

Base perforation according to DIN EN 50085

CD-HF 80X80 BU - Cable duct

3240601

<https://www.phoenixcontact.com/us/products/3240601>



Approvals



CSA

Approval ID: 248269



VDE Zeichengenehmigung

Approval ID: 40028972



EAC

Approval ID: RU C-DE.PB68.W.00513



UL Recognized

Approval ID: FILE E 328576

CD-HF 80X80 BU - Cable duct

3240601

<https://www.phoenixcontact.com/us/products/3240601>



Classifications

ECLASS

| | |
|---------------|----------|
| ECLASS-9.0 | 27400703 |
| ECLASS-10.0.1 | 27400703 |
| ECLASS-11.0 | 27400703 |

ETIM

| | |
|----------|----------|
| ETIM 8.0 | EC000012 |
|----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39131700 |
|-------------|----------|

CD-HF 80X80 BU - Cable duct



3240601

<https://www.phoenixcontact.com/us/products/3240601>

Environmental Product Compliance

| | |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
| | No hazardous substances above threshold values |

CD-HF 80X80 BU - Cable duct

3240601

<https://www.phoenixcontact.com/us/products/3240601>



Accessories

RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/us/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/us/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

CD-HF 80X80 BU - Cable duct

3240601

<https://www.phoenixcontact.com/us/products/3240601>



UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/us/products/1212478>

Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets



UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/us/products/1212509>

Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets



Phoenix Contact 2023 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com