




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:
203 888-2133



Home > 3/16 Hex Female Standoffs

3/16 HEX FEMALE STANDOFFS

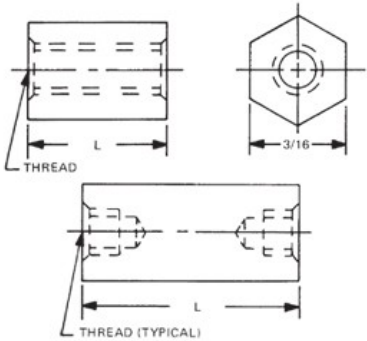

[Home](#) [Next](#)

[Related Metric](#)

Ordering Code			
xxxxx	xxx	xx	x
Length	Thread	Material	Finish

PART: 2055T 256 AL

Red ?'s show missing selections. [Help](#)

[Thread depth information](#)
[Material Specifications](#)
[Ordering non-standard items](#)
[Request a Drawing](#)

Add to Cart

Qty1 *

Qty2

Qty3

	20521	1132
☐	2053	1/4
☐	2053T	9/32
☐	2054	5/16
☐	2054T	11/32
☐	2055	3/8
☒	2055T	13/32
☐	2056	7/16
☐	2056T	15/32
☐	2057	1/2
☐	2057T	17/32
☐	2058	9/16
☐	2058T	19/32
☐	2059	5/8

Thread *		
Select	Code	Thread
☒	256	2-56
☐	440	4-40

Material *			
Select	Code	Material	RoHS
☒	AL	Aluminum	YES
☐	B	Brass	YES
☐	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES

Finish *

☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel
☐	6-Gold iridite*
☐	7-Clear iridite
☐	9-Alodine 1200*
☐	10-Bright chrome
☐	11-Satin chrome
☐	12-Zinc