

[Connectors](#) > [Pluggable IO Connectors & Cages](#) > [QSFP+/QSFP+](#)

1X4 QSFP KIT ASSY BHND BZL,PCI



✓ **ACTIVE**

QSFP/QSFP+

TE Part # **2170615-3**

TE Internal #: **2170615-3**

Form Factor : **QSFP+**

Product Type : **Cage Assembly**

Port Matrix Configuration : **1 x 4**

EMI Containment Feature Type : **Customer**

Applied Gasket

Included Heat Sink : **Yes**

 [Add to List](#) ▼

[Similar Products](#)



ORDER SAMPLES

Compatible Parts & Tooling

SHOP OUR DISTRIBUTORS

North America ▼

Request pricing, availability and customization options

CONTACT US



We are here to help!

Get in touch with our product experts.



CHAT WITH US



EMAIL US



CALL US

DOCUMENTS

FEATURES

PRODUCT COMPLIANCE

Product Drawings

1X4 QSFP KIT ASSY BHND BZL,PCI

 [1X4 QSFP KIT ASSY BHND BZL,PCI](#) English

CAD Files

3D PDF

 [3D_CVM_CVM_2170615-3_1_c-2170615-3-1-3d.pdf](#) 3D

Customer View Model

 [ENG_CVM_CVM_2170615-3_1_c-2170615-3-1.2d_dxf.zip](#) English

 [ENG_CVM_CVM_2170615-3_1_c-2170615-3-1.3d_igs.zip](#) English

 [ENG_CVM_CVM_2170615-3_1_c-2170615-3-1.3d_stp.zip](#) English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Form Factor : **QSFP+**

Product Type : **Cage Assembly**

Included Heat Sink : **Yes**


Cage Type : **Ganged**



	Connector System : Cable-to-Board Sealable : No Connector & Contact Terminates To : Printed Circuit Board
Configuration Features	Port Matrix Configuration : 1 x 4 Number of Ports : 4 Rear EONs per Port Column : 1
Electrical Characteristics	Data Rate (Max) (Gb/s): 28
Body Features	Heat Sink Style : Pin Heat Sink Height Class : Custom Heat Sink Height : 7.3 mm [.288 in] Heat Sink Finish : Anodized Black
Contact Features	PCB Contact Termination Area Plating Material : Tin
Termination Features	Termination Method to PC Board : Through Hole - Press-Fit
Mechanical Attachment	Connector Mounting Type : Board Mount
Housing Features	Cage Material : Nickel Silver
Dimensions	PCB Thickness (Recommended) : 1.45 mm [.057 in] Tail Length : 2.2 mm [.086 in]
Usage Conditions	Operating Temperature Range : -55 – 105 °C [-67 – 221 °F]
Operation/Application	Circuit Application : Signal For Use With : QSFP Cable Assembly, QSFP MSA Compatible Transceiver Application : Thermally Enhanced

Industry Standards	UL Flammability Rating : UL 94V-0
Packaging Features	Packaging Method : Box & Tray
Other	EMI Containment Feature Type : Customer Applied Gasket Included Lightpipe : No Enhancements : Thermally Enhanced
Statement of Compliance	Statement of Compliance pdf

Compatible Parts

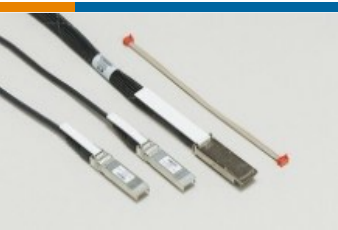

Pluggable I/O Cable Assemblies (53)



QSFP/QSFP+/zQSFP+ (1)



XFP (1)

Also in the Series | [QSFP/QSFP+](#)



Heat Sinks (1)



Pluggable I/O Cable Assemblies (60)



QSFP/QSFP+/zQSFP+ (173)

Customers Also Bought



TE Part # 2289129-2 ZQSFP+ CAGE& CONN 2X2, EMI SPRING, 4 LP	TE Part # 2007099-4 SFP+ 1x4 Light Pipe Assembly	TE Part # 1-2041035-4 RJ45 8P8C non-SHD P-GND T/D 50u" Au	TE Part # 2057353-1 SFP+ Enhanced 1x4 Cage Assy
--	---	--	--

