 



samtec



HPT-125-01-S-D-RA

HPT-134-01-L-D-RA

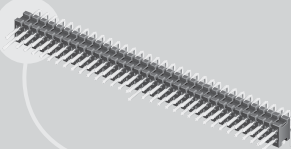

HOT PLUGGABLE HEADER HPT SERIES

SPECIFICATIONS

For complete specifications see www.samtec.com?HPT

Insulator Material:

Black Liquid Crystal Polymer



Terminal Material:

Phosphor Bronze

Current Rating:

1.75A @ 80°C ambient

Operating Temp Range:

-55°C to +125°C

Plating:

Sn or Au over 50µ" (1,27µm) Ni

RoHS Compliant:

Yes

Compact Flash & PCMCIA Compatible

APPLICATION SPECIFIC OPTION

Other pin counts and post heights available. Call Samtec.

Extended power and ground pins for first-mate-last-break applications

Right Angle Through-Hole for robust functionality

SMT Processing compatible insulators

(1,27mm x 1,27mm)
.050" x .050"
micro pitch

HPT

1

NO. PINS PER ROW

01

PLATING OPTION

D

RA

25, 34

(Call Samtec for other sizes)

-L

= 10µ" (0,25µm) Gold on contact, Matte Tin on tail

-S

= 30µ" (0,76µm) Gold on contact, Matte Tin on tail

Note: Some sizes, styles and options are non-standard, non-returnable.

Processing:

Max Processing Temp:

230°C for 60 seconds or

260°C for 20 seconds 3x


with Matte Sn plating

Lead-Free Solderable:

Wave, or reflow with Matte Sn plating




www.samtec.com

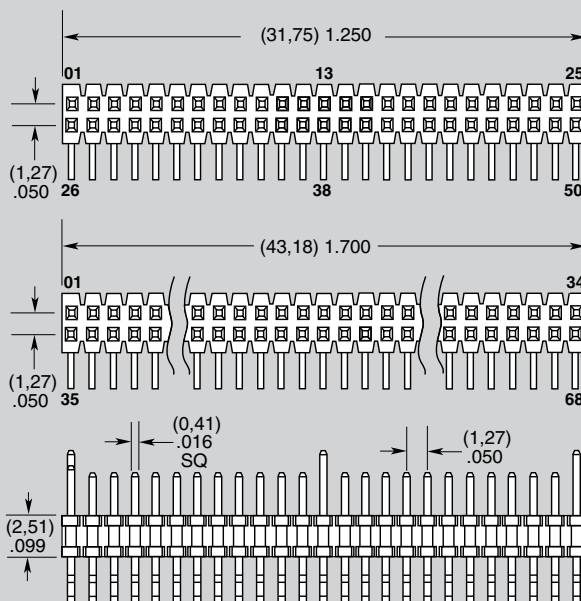

NO. PINS PER ROW	POSITION NO.	A
25	25, 26	(3,50) .138
	01, 13, 38, 50	(5,00) .197
	ALL OTHERS	(4,25) .167
34	01, 17, 34, 35, 51, 68	(5,00) .197
	36, 67	(3,50) .138
	ALL OTHERS	(4,25) .167

2 x 25 position is Compact Flash compatible.
2 x 34 position is PCMCIA compatible.

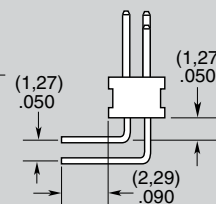

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 • Fax: 812-948-5047

SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0 • Fax: +49 (0) 89 / 89460-299

SAMTEC NORDIC/BALTIC • Tel: +46-84477280 • Fax: +46-844720413

SAMTEC JAPAN • Tel: 045-475-1385 • Fax: 045-475-1340

SAMTEC ISRAEL • Tel: 972-3-7526600 • Fax: 972-3-7526690

SAMTEC SILICON VALLEY • Tel: 408-395-5900 • Fax: 408-395-1520

SAMTEC FRANCE • Tel: 01 60 95 06 60 • Fax: 01 60 95 06 61

SAMTEC CHINA • Tel: 86-21-61103766 • Fax: 86-21-5423 4575

SAMTEC SOUTH AFRICA • Tel: 27 11 452 8112 • Fax: 27 86 6714432

SAMTEC UK • Tel: 01236 739292 • Fax: 01236 727113

SAMTEC ITALY • Tel: 39 039 6890337 • Fax: 39 039 6890315

SAMTEC INDIA • Tel: +91-80-3272 1612 • Fax: +91-80-4152 8187

SAMTEC TAIWAN • Tel: 886-2-2735-6109 • Fax: 886-2-2735-5036

SAMTEC ANZ • Tel: 613 9512 7747 • Fax: 613 9512 7745

SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 • Fax: 65 6841-1502

SAMTEC KOREA • Tel: 82-31-717-5685 • Fax: 82-31-717-5681