
 


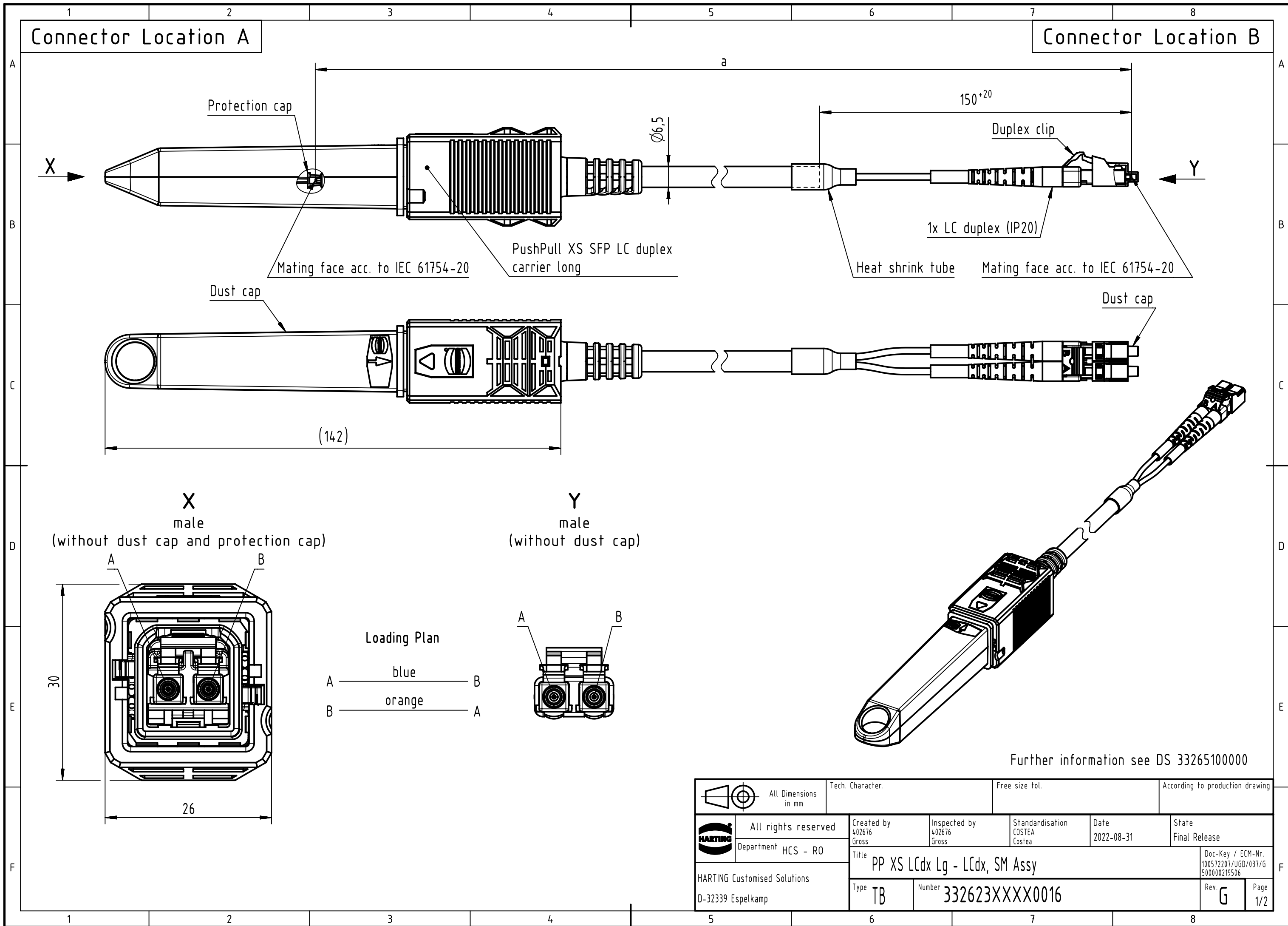

	1	2	3	4	5	6	7	8
A								
B								
C	28	33262311000016	F0 Cable, 2-channel, SM, 9/125µm, PUR, black	100	±1%			
	27	33262310900016		90				
	26	33262310800016		80				
	25	33262310700016		70				
	24	33262310600016		60				
	23	33262310500016		50				
	22	33262310450016		45				
	21	33262310400016		40				
	20	33262310350016		35				
	19	33262310300016		30				
D	18	33262310250016		25				
	17	33262310200016		20				
	16	33262310150016		15				
	15	33262310140016		14				
	14	33262310130016		13				
	13	33262310120016		12				
	12	33262310110016		11				
E	11	33262310100016		10	±0.03			
	10	33262310090016		9				
	9	33262310080016		8				
	8	33262310070016		7				
	7	33262310060016		6				
	6	33262310050016		5				
	5	33262310040016		4				
	4	33262310030016		3				
F	3	33262310020016		2				
	2	33262310010016		1				
	1	33262330500016		0.5				
	Cont. no.	Part no.	Type of cable	Dim. a[m]				
	1	2	3	4	5	6	7	8



All Dimensions
in mm

Tech. Character.

Free size tol.

According to production drawing



All rights reserved

Department HCS - RO

HARTING Customised Solutions

D-32339 Espelkamp

Created by
402676
Gross

Inspected by
402676
Gross

Standardisation
COSTEA
Costea

Date
2022-08-31

State
Final Release

Title
PP XS LCdx Lg - LCdx, SM Assy

Type
TB

Number
332623XXXX0016

Doc-Key / ECM-Nr.
100572207/UGD/037/G
500000219506

Rev.
G

Page
2/2