




+ CONNECTORS
RF CONNECTORS

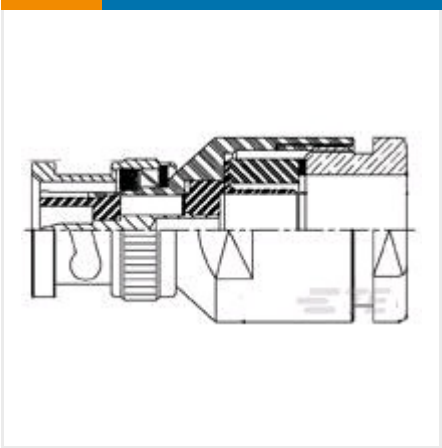

✓ Active

TE CONNECTIVITY (TE)
BNC Str Plg PS 75Ohm Silver URM70
Miniature Coax | PKG , STA

1-1478408-0
TE Internal Number: 1-1478408-0

EU RoHS Compliant with Exemptions
EU ELV Compliant with Exemptions

Connector Interface BNC
Connector Style Plug
Mated Outer Diameter (Approximate) 14.529 mm [.572 in]
Impedance (Ω) 75
Cable Type URM 70

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings
BNC STRAIGHT PLUG SOLDER (PS) 75 Ohm URM70
PDF
English

CAD Files
3D PDF
PDF
3D
Customer View Model
2D_DXF.ZIP
English

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

Instruction Sheets

Instruction Sheet (non U.S.)

GREENPAR RF CONNECTOR CABLE ASSEMBLY INSTRUCTION SHEET

PDF

English

GREENPAR RF CONNECTOR CABLE ASSEMBLY INSTRUCTION SHEET

TIF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector Interface BNC

Connector Style Plug

Sealable No

Connector & Contact Terminates To Wire & Cable

Configuration Features

Number of Positions 1

Electrical Characteristics

Impedance (Ω) 75

Body Features

Cable Connector Orientation Straight

Body Material Brass

Body Plating Material Silver

Contact Features

Center Contact Plating Material Silver

Center Contact Material Brass

Termination Features

Termination Method to Wire & Cable Clamp, Solder Terminal

Dimensions

Mated Outer Diameter (Approximate) 14.529 mm [.572 in]

Usage Conditions

Cable Type URM 70

Operation/Application

Operating Frequency (GHz) 2

Packaging Features

Packaging Method Box

Packaging Quantity 50

Other

Dielectric Material PTFE

Gasket Material Silicone Rubber

Coupling Nut Material Brass

Grade Professional

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF