


Solder pin angled .318"
with Ferrit, metal bracket,
threaded insert and clip

Directive 2002/95/EC
„RoHS“
Compliant

(click on the schematic(s) for a more detailed view)

Socket Connector

Plug Connector

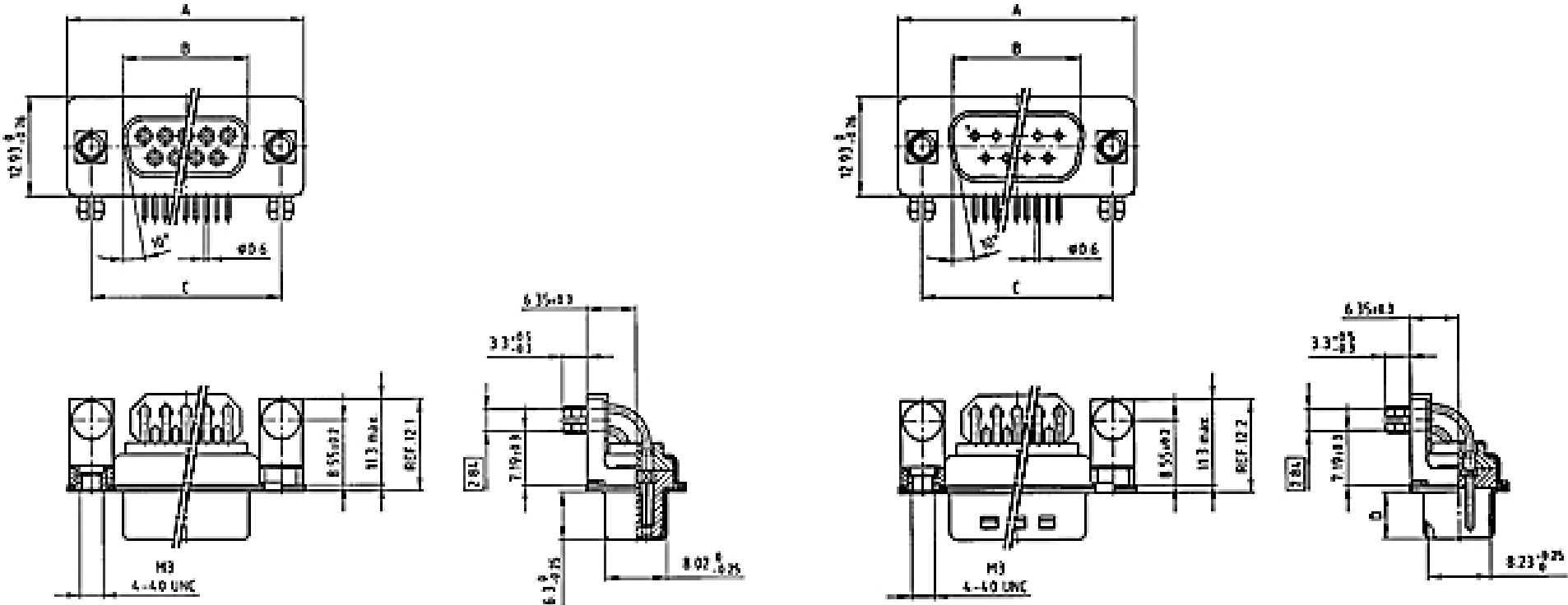

Socket Connector			
No. of pos.	A - 0,76	B - 0,25	C
09	31,19	16,46	25,00 + 0,12 - 0,13
15	39,52	24,79	33,30 + 0,15 - 0,10
25	53,42	38,50	47,04 ± 0,13
37	69,70	54,96	63,50 ± 0,13

Plug Connector				
No. of pos.	A - 0,76	B + 0,25	C	D - 0,30
09	31,19	16,79	25,00 + 0,12 - 0,13	6,12
15	39,52	25,12	33,30 + 0,15 - 0,10	6,12
25	53,42	38,84	47,04 ± 0,13	5,99
37	69,70	55,30	63,50 ± 0,13	5,99

Part Numbers

Socket connector		
No. of Pos	UNC 4-40	M 3
09	242 A 24260 X	242 A 24300 X
15	242 A 24270 X	242 A 24310 X
25	242 A 24280 X	242 A 24320 X
37	242 A 24290 X	242 A 24330 X

Plug connector		
No. of Pos	UNC 4-40	M 3
09	241 A 24360 X	241 A 24400 X
15	241 A 24370 X	241 A 24410 X
25	241 A 24380 X	241 A 24420 X
37	241 A 24390 X	241 A 24430 X



REG.-Nr. 40000441



File #: E202784



File #: LR115000