



Dura-Con High Reliability Back Shells-MMBS

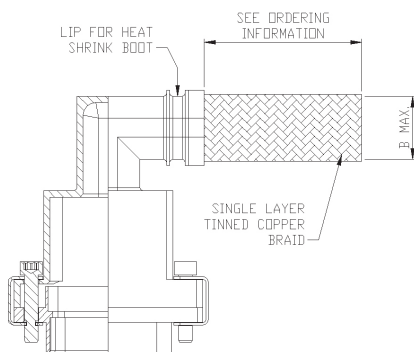


FEATURES


- **MMBS is a complete range of EMC protected back shells, delivered with their braid at specified length available in all shell sizes and 4 cable entry types.**

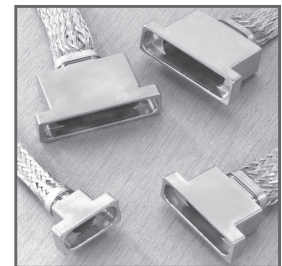


R
Top Entry 90°

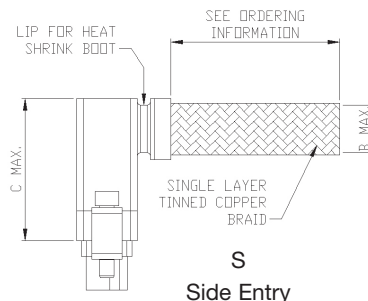

S
Side Entry

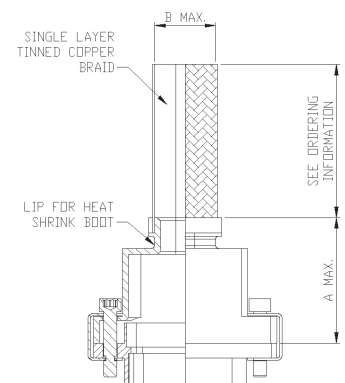

T
Top Entry

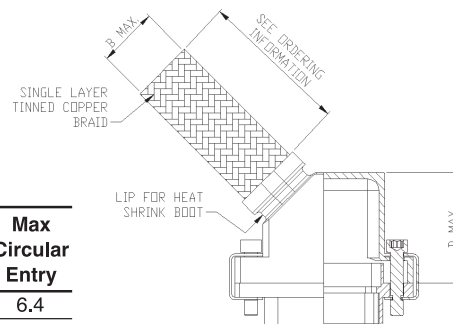

F
45° Entry

Dimensions Table

Shell size	A Max	C Max	D Max	Max Circular Entry
9	17.5	16.0	17.0	6.4
15	17.5	16.5	18.0	6.4
21	17.5	17.5	19.0	6.4
25	20.5	18.5	21.0	6.4
31	20.5	19.0	22.0	6.4
37	25.5	19.0	24.0	6.4
51	25.5	22.0	25.0	7.9
100	30	25.5	27.0	9.5

Entry Size Table

Entry size	B Max
04	3.2
05	4.0
06	4.8
07	5.6
08	6.4
09	7.1
10	7.9
11	8.7
12	9.5
13	11.1
14	12.7
15	14.3
16	15.9
17	17.5

Ordering Information

MM BS F 21 05 C 18

Microminiature back shell ————

Entry Type ————

F = 45°
T = Top entry
R = 90°
S = Side entry

Shell size ————

9, 15, 21, 25, 31, 37, 51, 100

Braid length
In 1" increments

Back shell plating
C = Yellow chromate cadmium
N = Electroless nickel

Entry size
See above table

Entry sizes 13 to 17 only available for side entry style. Oval spouts also available upon request.