

Search

Amphenol Pcd #

Find


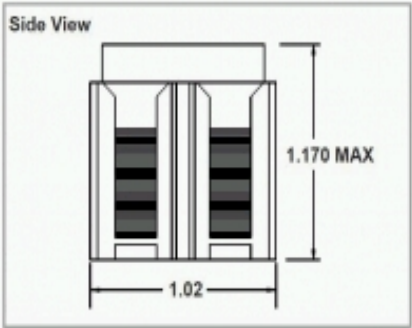
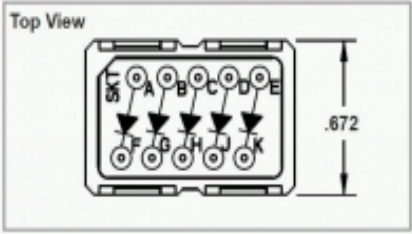
Cross Reference #

Find

Locate inventory

Find

SJE020063

Series:	Series 2
Type:	Electronic
Number of Contacts:	10
Number of Contacts per Size:	10
Contact Size:	20
Contact Type:	Socket
Contact Part Number:	M39029/22-192
QPL:	Not QPL'd
Mil-Spec:	N/A
Temperature (C°):	-65 to 200
Insulation Resistance:	5000 Megaohms Min. at 25 degrees Celcius
Dielectric Withstanding Voltage:	1500 VRMS at Sea Level 200 VRMS at 100,000 Ft.
Amperage:	7.5 Amps
Vibration and Shock:	MIL-T-81714 Paragraph 3.5.5 and 3.5.8
Body:	Polyetherimide per ASTM-D5205
Grommet:	Silicone Blend Elastomer per A-A-59588
Contact Retainers:	Stainless Steel
Socket/Pin Contacts:	Copper Alloy, Hard Gold Plated in Accordance with MIL-G-45204
With or Without:	With
Color:	Brown
Electronic Component Type:	Diode
Electronic Component Part No.:	JANTX1N3613
Electronic Req. Qty:	5
Engineering PDF:	 SJE020063_C.pdf
Dimension Image:	<div><div>Side View</div><div>Top View</div></div>
Bussing or Circuit Configuration:	Contact factory for drawing.