
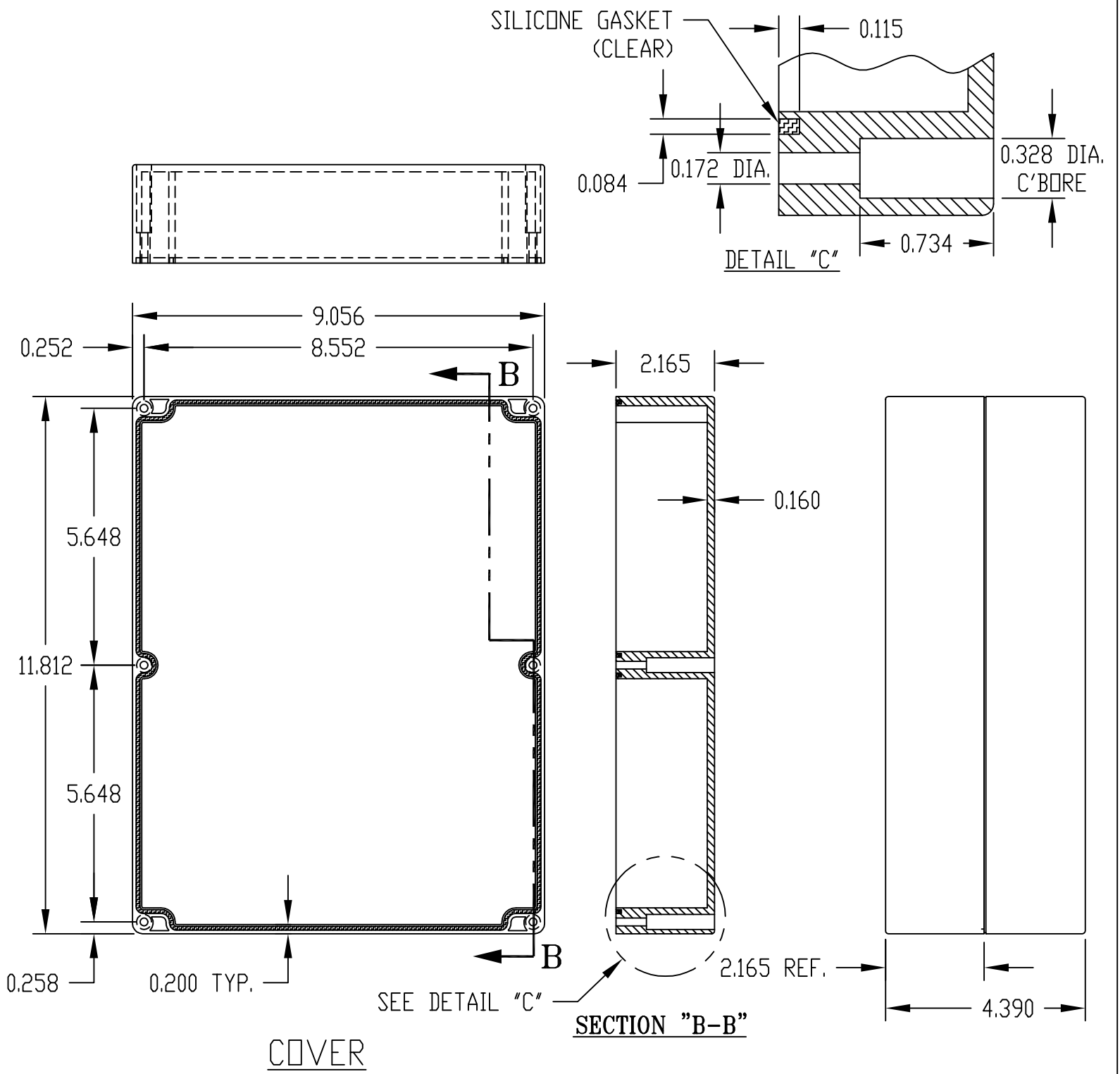


|           |                   |          |                                   |           |          |
|-----------|-------------------|----------|-----------------------------------|-----------|----------|
| PART NAME | NEMA 4X ENCLOSURE | PART No. | PN-1343, PN-1343-C AND PN-1343-DG | REV. DATE | 11-17-08 |
|-----------|-------------------|----------|-----------------------------------|-----------|----------|

INDUSTRY STANDARDS:  
 POLYCARBONATE (LIGHT GRAY AND CLEAR)  
 UL94-HB FLAMMABILITY RATING (UL FILE #E41613)  
 UV STABILIZED  
 SERVICE TEMPERATURE RANGE: -40°C TO +120°C  
 ABS (DARK GRAY)  
 UL94-HB FLAMMABILITY RATING (ULFILE #E560700)  
 SERVICE TEMPERATURE RANGE: -40°C TO +80°C

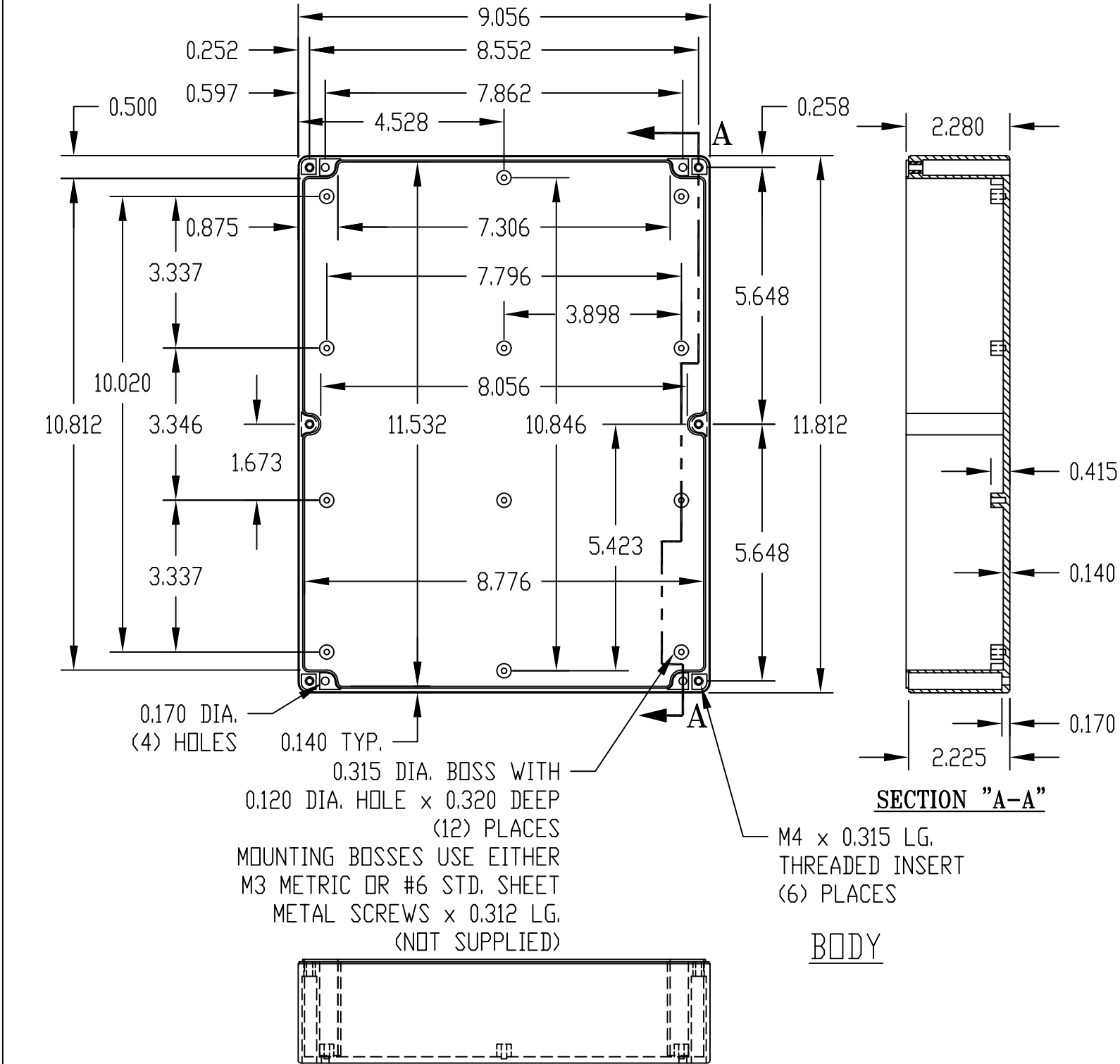

NOTE: ALL DIMENSIONS HAVE ±0.015 TOLERANCE UNLESS OTHERWISE SPECIFIED.

| PART NUMBER | MATERIAL        |       | FINISH     |       | HARDWARE KIT                                                      |
|-------------|-----------------|-------|------------|-------|-------------------------------------------------------------------|
|             | BODY            | COVER | BODY       | COVER |                                                                   |
| PN-1343     | POLYCARBONATE   |       | LIGHT GRAY |       | KIT CONTAINS (6)<br>M4 x 25mm (1.000") LG.<br>SCREWS FOR ASSEMBLY |
| PN-1343-C   | POLYCARBONATE   |       | LIGHT GRAY | CLEAR |                                                                   |
| PN-1343-DG  | HIGH-IMPACT ABS |       | DARK GRAY  |       |                                                                   |