


Product Line

- Single Pair Ethernet >
- ZConnect >
- Ceres >
- X-Lok >
- M Series >**
 - Accessory
 - M5
 - Guided M8
 - M8
 - M10.5
 - M12 (A)**
 - M12 (B)
 - M12 (D)
 - M12 (I)
 - M12 (K)
 - M12 (L)
 - M12 (S)
 - M12 (T)
 - M12 (V)
 - M23
 - FL0S & FL0S+ >
 - Power >
 - RBL >
 - HS-Lok >
 - NMEA 2000 >
 - Heavy Duty Shielded >
 - RJ >
 - USB >
 - SSL >
 - HDMI >
 - DVI >
 - Fiber Optic >
 - RF >
 - Cable Joiner >
 - Cable Gland >
 - Pressure Relief Vent >
 - LED Light Guide >
 - D-Sub >

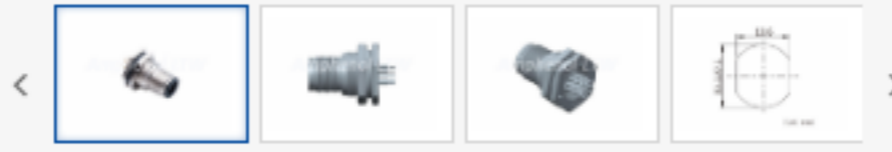

M12A-12PMMP-SF8002

Operating Temperature: -40°C ~ +105°C
 Transmission Speed: N/A
 Shielded: Metal, Non-shielded
 Jacket Material: N/A
 Certificate: UL1977, UL2238, UL1863

You must login first for view the price

Quantity **Check Stock**

Add to Cart **Inquiry**

Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type **Search**

M Series, Accessory...
CAP-WBDMQPC1
-20°C ~ +80°C

M Series, Accessory...
CAP-WBDM SMA1
-40°C ~ +105°C

M Series, Accessory...
CAP-WBDM SMA2
-40°C ~ +105°C

M Series, Accessory...
CAP-WBDM SPB2
-40°C ~ +105°C

ABOUT AMPHENOL LTW **SUPPORT** **PARTNERS** **DOWNLOAD CENTER** **FEEDBACK**

Add to Cart

Inquiry

Specifications	Download / CAD
Nominal Current 1.5A	Connector Type Receptacle
Shielded Metal, Non-shielded	No. of Contacts 12
Connector Gender Male	Backshell Hexagonal
Mating Style Screw Thread	IP Rating IPX8
Assembly Style PCB 180°	
More Options	

People Also Bought