

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300170004

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Field Attachable, Female Connector, 3 Pole, Cable Range: 5.08-11.43mm Outside Diameter with Internal Threads

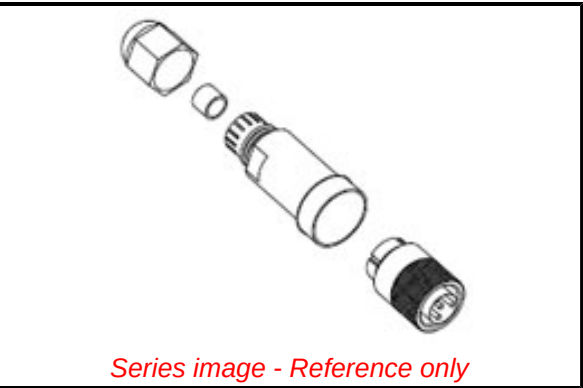

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	130017
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Field Attachable Connector
UPC	78172553098
Physical	
Cable Diameter	5.08-11.43mm (.200-.450")
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Single
Material - Connector Body	Nylon
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	47.000/g
Orientation	Straight
Poles	3
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	15 to 24
Electrical	
Current - Maximum per Contact	13.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1A3000-34
Reference - Drawing Numbers	
Sales Drawing	SD-130017-002

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

130017 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION