


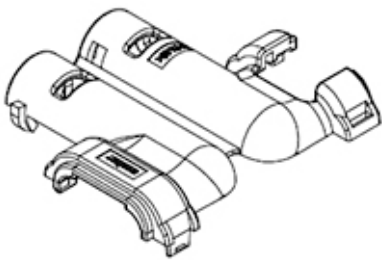

**Part Number :** [1600914120](#)  
**Product Description :** MXP120 Backshell, Exit Direction Right, Flange Size NW 7.5, with Cable Tie Access, 4 Circuits  
**Series Number :** [160091](#)  
**Status :** Active  
**Product Category :** [Connector Accessories](#)



## Documents & Resources

**Drawings**  
[1600914120\\_sd.pdf](#)  
[PK-31302-118-001.pdf](#)

**3D Models and Design Files**  
[1600914120\\_stp.zip](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Not Relevant
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Part Details

### General

Status	Active
Category	Connector Accessories
Series	160091
Description	MXP120 Backshell, Exit Direction Right, Flange Size NW 7.5, with Cable Tie Access, 4 Circuits
Application	Automotive
Component Type	Cover
Product Name	MXP120 Sealed
UPC	889056640688

### Physical

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	4.220/g
Packaging Type	Bag
Temperature Range - Operating	-40° to +125°C

---

### Use with Part(s)

Description	Part Number
MXP120 Sealed Receptacle Housings	<u>34900</u>

---

---

This document was generated on Apr 26, 2025