


DUST COVER ASSEM

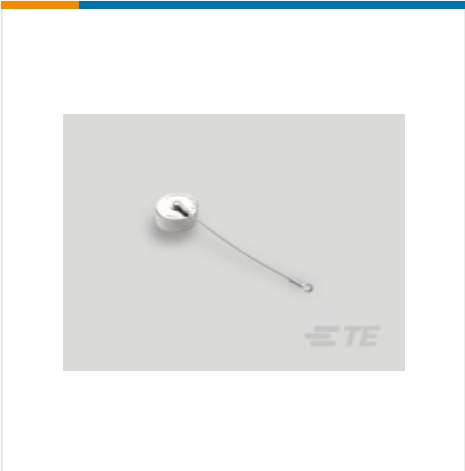

DEUTSCH | DEUTSCH 38999 Metal Covers

TE Part # **DTS33F09N [V001]**
TE Internal #: **YDTS33F09NV0010000**
Mil-Spec: **D38999/33F9N**

Accessory Type : **Protective Cover**
Shell Size : **9**
Cap to Flange Attachment : **Wire Rope with PTFE Coating**
Sealable : **Yes**
Operating Temperature Range : **-65 – 175 °C**
[-85 – 347 °F]

[Similar Products](#)

ORDER SAMPLES

Compatible Parts & Tooling

SHOP OUR DISTRIBUTORS

North America

[See all price breaks](#)

Distributor	1	10,000	Buy
AVNET ELECTRONICS	97 in stock		Visit Site
PEI-GENESIS	48 in stock		Visit Site

We are here to help!
Get in touch with our product experts.

CHAT WITH US

EMAIL US

CALL US

DOCUMENTS

FEATURES

PRODUCT COMPLIANCE

Product Drawings

DUST COVER ASSEM

DUST COVER ASSEM English

CAD Files

3D PDF

3D_CVM_CVM_YDTS33F09NV0010000_1.pdf

3D

Customer View Model

ENG_CVM_CVM_YDTS33F09NV0010000_1.2d_dxf.zip English

ENG_CVM_CVM_YDTS33F09NV0010000_1.3d_igs.zip English

ENG_CVM_CVM_YDTS33F09NV0010000_1.3d_stp.zip English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features	Accessory Type : Protective Cover Shell Size : 9 Sealable : Yes
Body Features	Sealing Gasket Material : Silicone Cap Material : Metal Sealing Cap Material : Aluminum Sealing Cap Plating Material : Nickel
Mechanical Attachment	Cap to Flange Attachment : Wire Rope with PTFE Coating
Dimensions	Length : 127 mm [5 in]
Usage Conditions	Operating Temperature Range : -65 – 175 °C [-85 – 347 °F]
Statement of Compliance	Statement of Compliance pdf

Also in the Series | [DEUTSCH 38999 Metal Covers](#)

[Circular Connector Caps & Covers \(144\)](#)

