



Street Lighting

LED made easy

Ver 17.09

LedLink



Ledlink Optics, Inc

Taiwan(HQ):
15F, No.655,Bannan Rd.,
Chung - Ho Dist, New Taipei City,
Taiwan 235

Ledlink Optics(Dong Guan) Co., Ltd




Dong-Guan(Factory):
No.5, TianKeng Industrial District
HengLi Town, DongGuan City
GuangDong Province China 523478

Ledlink Optics(Yang Zhou) Co., Ltd

Yang-Zhou(Factory):
No.180,LinJiang Road,Yangzhou City,
Jiangsu Province,China

| service@ledlink-optics.com | www.ledlink- optics.com

LED Package size

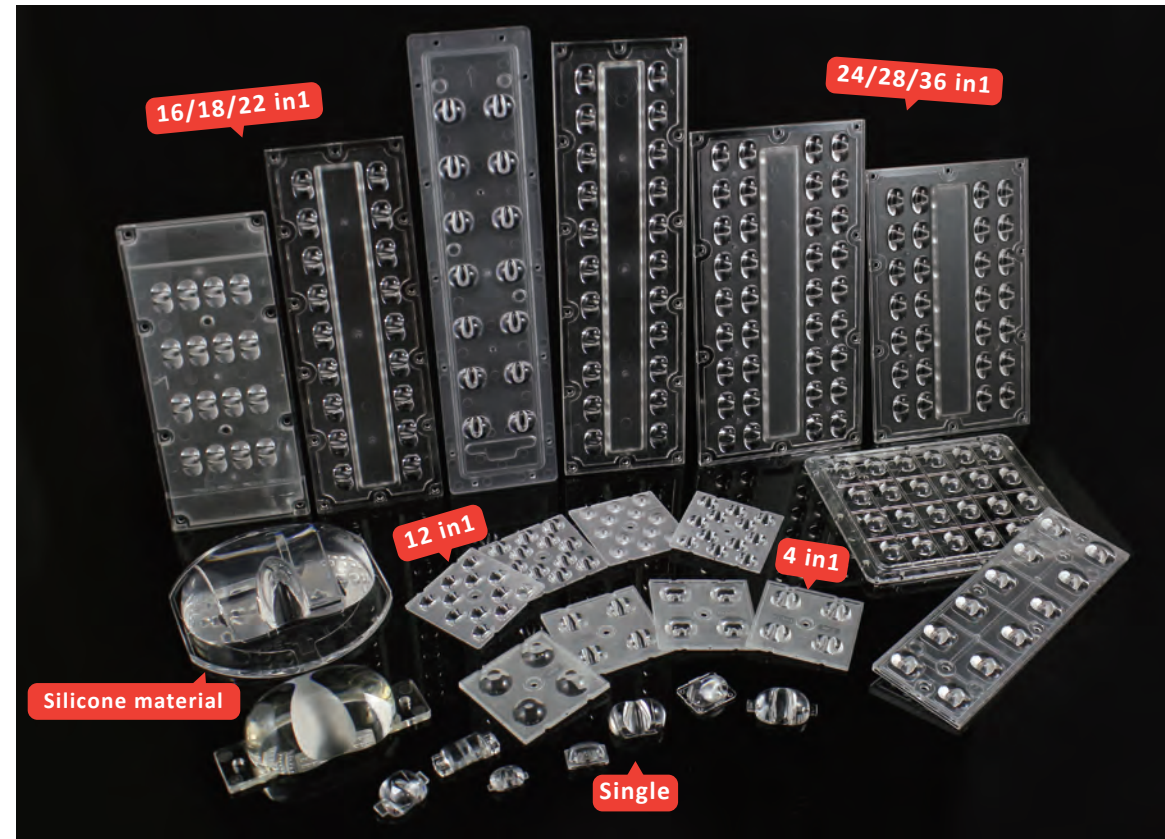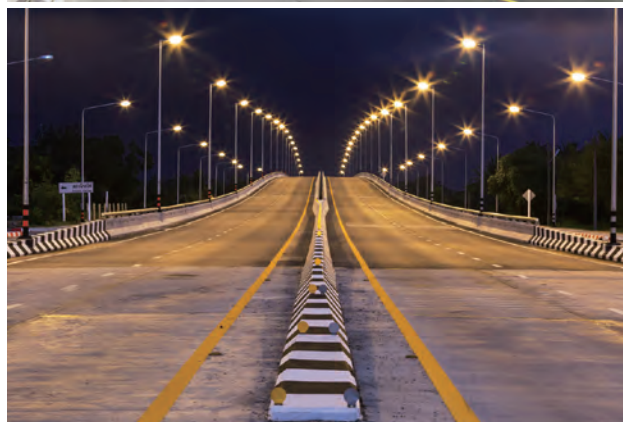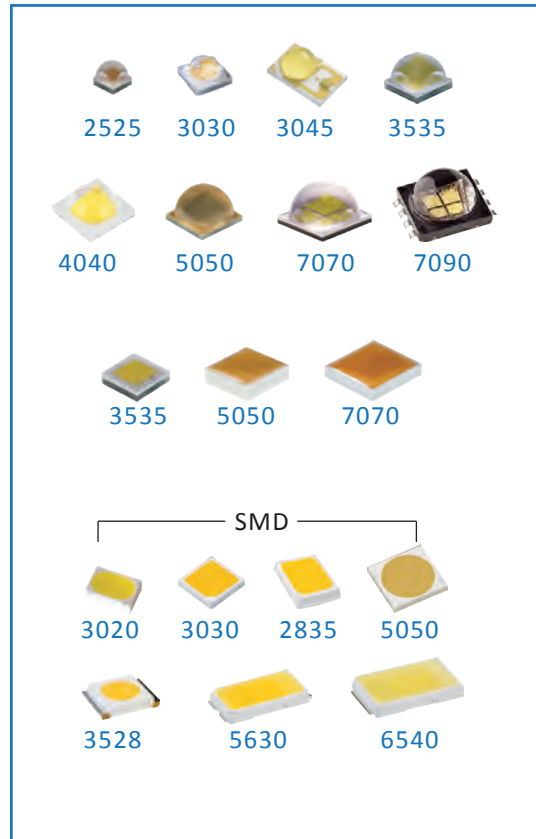

Single

Tape available

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
I-VS	LL01CR-KM6090L02 T	60x90°	17.55x11.6x8.6	2525/3535/ 3030(SMD) 3045	Illuminance	Symmetrical
	LL01CR-FT60135L02	60x135°	18x9.3x5.9	2525/3535/ 3030(SMD) 3045/4040/ 5050(SMD)		
I-S	LL01OS-AU60140L02	60x140°	16x8.8x5.3	2525/3535/ 3030(SMD) 3045	Illuminance	Asymmetrical
	LL01CR-OW70130L02	70x130°	17.4x12.75x7.2	2525/3535/ 3030(SMD) 3045/4040/ 5050(SMD)		
	LL01CR-AU85135L02	85x135°	18x10.2x6.1	2525/3535/ 3030(SMD) 3045/4040		
	LL01CR-BAJ85135L02 T	85x135°	18x12.5x6.1	2525/3535/ 3030(SMD) 4040		
	LL01CR-AEC30140L02	30x140°	22x19x10	5050(SMD)		
	LL01CR-PB70140L02	70x140°	22.4x11.4x6.9	2525/3535/ 3030(SMD) 4040/ 5050(SMD)		
	LL01ED-AU70120L02	70x120°	94x42x28.4	LES:Φ9.9/Φ16/Φ18.4/Φ19 Φ23/Φ29.2/Φ32	Brightness	Asymmetrical
	LL01CR-XW70140L02	70x140°	32x17.6x9.8	3535/7070/ 5050(SMD)		
	LL01CR-APM80150L02 T	80x150°	18x12.5x6.95	2525/3535/ 3030(SMD) 3045/4040/ 5050(SMD)		
	LL01LU-UQ70140L02	70x140°	18x11x6.6	3535/3045/ 3030(SMD) 4040/ 5050(SMD)	Illuminance /Brightness	Asymmetrical
II-S	LL01LU-AEV50150L02 T	50x150°	18x12.5x6.3	3535/3045	Brightness	Asymmetrical
	LL01LU-AGV80150L02	80x150°	32x18.5x9.5	3535/7070/ 5050(SMD)		
	LL01LU-AIK45135L02 T	45x135°	18x12.5x7.05	2525/3535/ 3030(SMD) 3045/4040	Illuminance	Asymmetrical
	LL01CR-AU45135L46	45x135°	18.5x13.5x8.53	5050(SMD)		

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
II-M	LL01CR-OG85150L02	85x150°	18x8.95x6.2	3535/3045/ 3030(SMD)	Illuminance	Symmetrical
III-S	LL01ZZ-AGX45155L02 T	45x155°	18x12.5x7	2525/3045/3535/ 3030(SMD)	Brightness	Asymmetrical
	LL01CR-APM95165L19	95x165°	18x12.5x6.54	5050(SMD)		
V-M	LL01CR-CXE165L19	165°	18x18x5.8	3535/ 3030(SMD)	Illuminance	Symmetrical

Silicone material

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
I-M	LL01CR-CQW60155L100	60x155°	99.7x110.5x30.98	LES:Φ6.5/Φ22/Φ23	Illuminance	Symmetrical
II-M	LL01CR-CQW90155L100	90x155°	100x110.5x31.67	LES:Φ6.5/Φ22/Φ23	Illuminance	Asymmetrical
III-M	LL01CR-CQW45150L100	45x150°	99.7x110.5x32.78	LES:Φ6.5/Φ22/Φ23		

2 in1

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
II-S	LL02CR-AUH45135L46	45x135 °	50x24.8x8.5	5050(SMD)	Illuminance	Asymmetrical
	LL02CR-AUV45135L46					

8 in1

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
II-S	LL08BR-DCB35140L52 Silicone gasket: LL01A005WX2	35x145°	118.3x70.3x9.7	5050(SMD)	Illuminance	Asymmetrical

4 in1

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
I-S	LL04CR-CGM85135L02	85x135 °	50x50x6.9	3535/ 3030(SMD)	Illuminance	Asymmetrical
II-S	LL04CR-AU45135L46	45x135 °	50x50x8.3	5050(SMD)		
	LL04BR-WAU35140L52 <i>Silicone gasket : LL01A00SVX2</i>	35x145 °	65x65x9.9	5050(SMD)		
	LL04CR-BXJ80150L02	80x150 °	50x50x7.05	2525/3045/ 3030(SMD) 3535/4040/ 5050(SMD)	Brightness	Asymmetrical
II-M	LL04CR-CFN35155L02	35x155 °	50x50x6.5	3535/ 3030(SMD)		
III-S	LL04CR-BXJ45155L02	45x155 °	50x50x6.95	2525/3045/ 3030(SMD) 3535/4040/ 5050(SMD)		
	LL04CR-BXJ95165L19	95x165 °	50x50x4.2	5050(SMD)		
III-M	LL04CR-CFN60155L02	60x155 °	50x50x7.3	3535/ 3030(SMD)		
IV-M	LL04CR-BXJ65165L19	65x165 °	50x50x6.97	5050(SMD)	Illuminance	Asymmetrical
V-S	LL04CR-BXJ60L02	60 °	50x50x7.3	3535/ 3030(SMD) 7070/ 5050(SMD)	Brightness	Symmetrical
	LL04CR-BXJ90L02	90 °	50x50x7.3	3535/ 3030(SMD) 7070/ 5050(SMD)		
V-M	LL04CR-CXE165L19	165 °	50x50x5.8	3535	Illuminance	Symmetrical
	LL04CR-CXR165L19	165 °	50x50x6.68	5050(SMD)		

16/18/22 in1

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
I-S	LL16SE-BQL45145L51	45x145°	167.6x73.6x7.6	3030(SMD) /4040 5050(SMD)	Brightness	Asymmetrical
	LL18SE-CBZ50150L51 <i>Silicone gasket : LL01A0XRVQX2</i>	50x150°	198x68x7.6	3030(SMD) /4040 5050(SMD)		
	LL22SE-CBZ50150L51 <i>Silicone gasket : LL01A0XVRX2</i>	50x150°	238x68x7.6	3030(SMD) /4040 5050(SMD)		

12 in1

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
I-S	LL12OS-EL50130L02	50x130°	158.4x50.3x9.1	5050(SMD)	Illuminance	Asymmetrical
II-S	LL12ZZ-CRC45145L19	45x145 °	50x50x5.3	2835 SMD/3535/ 3030(SMD)	Brightness	Asymmetrical
	LL12CR-CUQ60145L02 <i>Silicone gasket : LL01A00RSQX2</i>	60x145°	173x71.4x 7.7	3535		
II-M	LL12ZZ-CRC45155L19	45x155 °	50x50x5.3	2835 SMD / 3030(SMD)		
III-S	LL12ZZ-CRC60145L19	60x145 °	50x50x4.9	3030(SMD)		
	LL12ED-VT85160L02	85x160°	158x50x9.4	5050(SMD)		
III-M	LL12ZZ-CRC60155L19	60x155 °	50x50x5.1	3030(SMD)		
IV-S	LL12ZZ-CRC75140L19	75x140 °	50x50x4.6	3030(SMD)		
V-M	LL12ZZ-CRC150L19	150 °	50x50x4.05	3030(SMD)	Illuminance	Symmetrical

24/28/36 in1

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
II-S	LL24CR-AU75135L02 <i>Silicone gasket :LL01A00RAAP7</i>	75x135°	120x100x10.2	3045/ 3030(SMD) 3535/ 5050(SMD)	Illuminance	Asymmetrical
I-S	LL28SE-CBZ50150L51 <i>Silicone gasket : LL01A0XRVSX2</i>	50x150°	158.3x98.03x7.6	3030(SMD) /4040 5050(SMD)	Brightness	Asymmetrical
I-S	LL36SE-CBZ50150L51 <i>Silicone gasket : LL01A0XRVTX2</i>	50x150°	188x98x7.6	3030(SMD) /4040 5050(SMD)	Brightness	Asymmetrical

140 in1

Type	Part number	FWHM	DxWxH (mm)	LED Package size	Specification	
II-VS	LL140SE-CKT45130L51 <i>Silicone gasket: LL01A00SYX2</i>	45x130°	272.6x123.6x9.2	3030(SMD)	Illuminance	Asymmetrical