




+ CONNECTORS

AUTOMOTIVE, TRUCK, BUS, & OFF-ROAD HOUSINGS

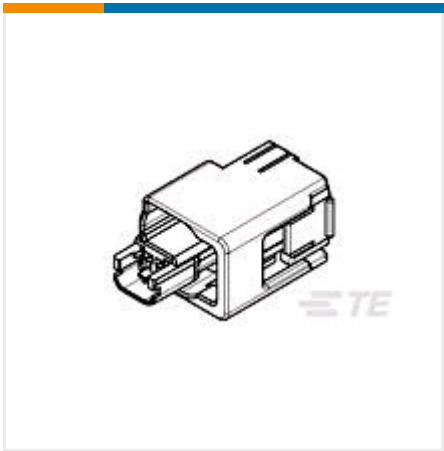

✓ Active

TE CONNECTIVITY (TE)
0.64MM, 2POSN SEALED PLUG, BLA
TH/.025 Connector System

1438426-1
TE Internal Number: 1438426-1

- EU RoHS Compliant
- EU ELV Compliant
- Mating Tab Width .64 mm [.025 in]
- Connector System Wire-to-Wire
- Number of Positions 2
- Centerline (Pitch) 2.54 mm [.1 in]
- Sealable Yes

↓ **PRODUCT DRAWING**
English

↓ **3D PDF**

DOCUMENTATION

Product Drawings

CONNECTOR ASSEMBLY, FEMALE, 2 POSITION SEALED, 0.64mm

PDF (TIFF AVAILABLE)

English

CAD Files

Customer View Model

2D_DXF.ZIP

English

3D PDF

PDF

3D

Customer View Model

3D_IGS.ZIP

English

Customer View Model

3D_STP.ZIP

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Connector System Wire-to-Wire

Sealable Yes

Hybrid Connector No

Strain Relief No

Configuration Features

Number of Positions 2

Number of Rows 1

Body Features

Color Black

Body Material Other

Contact Features

Mating Tab Width .64 mm [.025 in]

Mechanical Attachment

Mounting Feature No

Terminal Position Assurance No

Polarized No

Housing Features

Centerline (Pitch) 2.54 mm [.1 in]

Dimensions

Width 16.45 mm [.6476 in]

Height 35.3 mm [1.389 in]

Length 20.61 mm [.8114 in]

Operation/Application

Circuit Application Signal

Industry Standards

UL Flammability Rating UL 94-HB

Agency/Standard SAE/USCAR-2

Packaging Features

Packaging Method Package

Packaging Quantity 25

Other

Connector Position Assurance Capable Yes

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
