




Color: ■ black

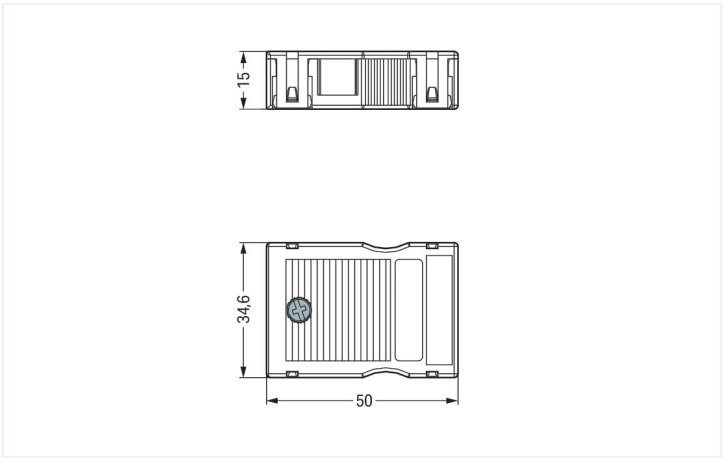

Dimensions in mm

Strain relief housing *WINSTA*® MIDI 3-pole

The strain relief housing from the *WINSTA*® MIDI product line guarantees you the greatest possible flexibility in electrical installation. A comprehensive range of accessories rounds out the *WINSTA*® product line from WAGO. The *WINSTA*® MIDI product line guarantees flexibility for the installation. Through its Push-in CAGE CLAMP® spring pressure connection technology, it achieves error-free, time-saving installation and offers flexibility and customization for meeting all installation requirements. The strip length is 55 mm.

WINSTA® MIDI solutions for your electrical installation – protected against mismatching and maintenance-free

WINSTA® is the pluggable connection system that is optimally tailored to the strict requirements of electrical installation. It ensures error-free installation of cables and components, quickly and reliably. Choose durability and quality – with protection against mismatching from WAGO makes the installation of electrical components substantially easier.

- simple circuits
- quick replacement of defective units during ongoing operation

Connection data	
Connection 1	
Pole number	3
Connectable sheathed cable diameter	4.5 ... 8 mm
Strip length (outer insulation)	55 mm



Physical data	
Pin spacing	10 mm / 0.394 inches
Width	34.6 mm / 1.362 inches
Height	15.2 mm / 0.598 inches
Depth	50 mm / 1.969 inches


Material data	
Note (material data)	Information on material specifications can be found here
Color	black
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.5 MJ
Weight	10.3 g

Environmental requirements	
Processing temperature	-5 ... +40 °C
Continuous operating temperature	-35 ... +85 °C
Note on continuous operating temperature	Insulating parts for temperatures ≤ 105 °C

Commercial data	
Product Group	20 (Winsta)
eCl@ss 10.0	27-44-06-92
eCl@ss 9.0	27-44-06-92
ETIM 8.0	EC002863
ETIM 7.0	EC002863
PU (SPU)	50 pcs
Packaging type	Box
Country of origin	DE
GTIN	4044918057516
Customs tariff number	39269097900

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Approvals / Certificates

General approvals			Approvals for marine applications		
					
Approval	Standard	Certificate Name	Approval	Standard	Certificate Name
cURus Underwriters Laboratories Inc.	UL 1977	E45171	DNV GL Det Norske Veritas, Ger- manischer Lloyd	-	TAE00001Z6



Downloads			
Environmental Product Compliance			
Compliance Search			
Environmental Product Compliance	770-503/023-000		

Documentation			
Bid Text			
770-503/023-000	19.02.2019	xml 2.74 KB	
770-503/023-000	12.03.2015	doc 23.50 KB	

CAD/CAE-Data			
CAD data		CAE data	
2D/3D Models	770-503/023-000	EPLAN Data Portal	770-503/023-000
		WSCAD Universe	770-503/023-000
		ZUKEN Portal	770-503/023-000

1 Compatible Products
1.1 Optional Accessories
1.1.1 Marking
1.1.1.1 Marking strip



Item No.: 210-333
Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive; white

1.1.2 Shield termination
1.1.2.1 Shield termination



Item No.: 770-523
Shield connecting plate; 3-pole; for sockets and plugs; silver-colored

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com