

BPSF00101045100M00

Search by :

- Part Number
- Characteristics
- Cross reference



MP


?

Closed Magnetic Circuit Type

Series Pdf

Product detail		
L (mm) ±		10.1±0.3
W(mm) ±		10.1±0.3
T (mm) ±		4.5±0.3
Inductance(uH)		10
Tolerance(±%)		20
Test Frequency		0.5V 1kHz
RDC(ohm)		0.0364
RDC Tolerance(±%)		20
Isat(A)		3
Irms(A)		2.5

- Part Numbering
- Dimensions
- Packing
- Recommended Pattern
- Electrical Characteristics

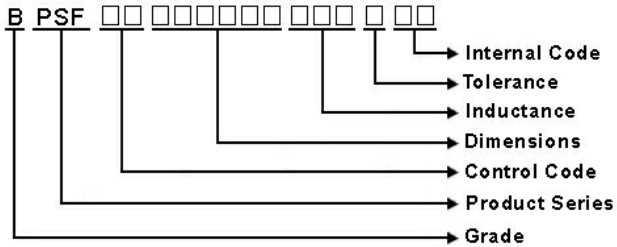

Products

- Power Inductor
- EMI-Noise Suppression
- RF-Signal Inductor
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

- Media Center
- New Products

Contact Us

Contact Info

Contact Form

Join Chilisin

Terms of Use

Privacy policy

Sitemap



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.