


Edge protection grommets : HV1201


Edge protection grommets black, Article number: 633-02010

 Add to watchlist

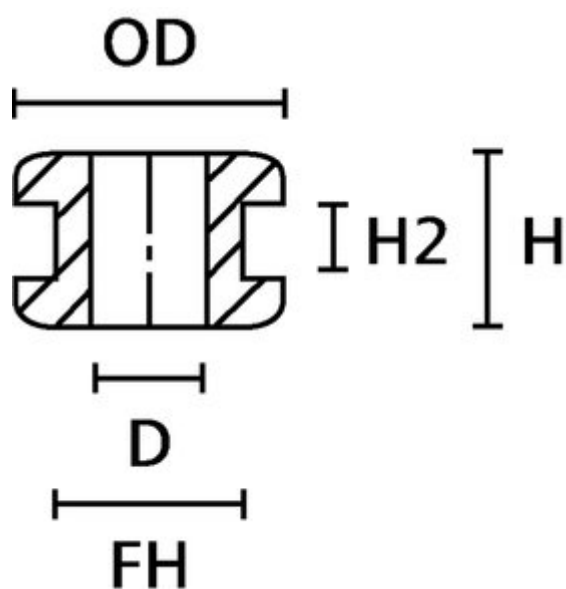

 Images (7)

 Downloads

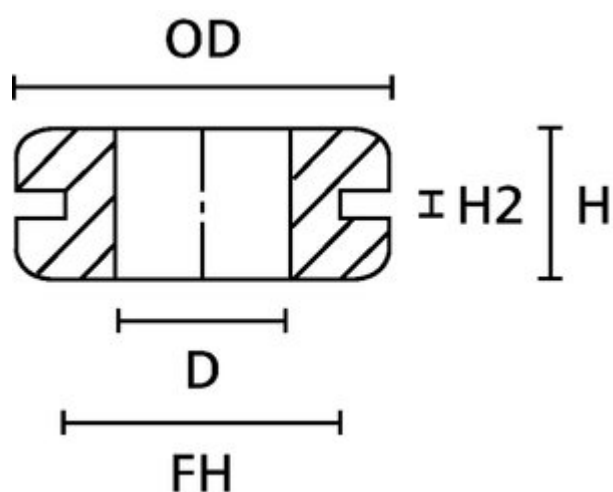

Features

- Protects cables from sharp edges
- Provides additional strain relief
- Flexible and easy to apply
- High resistance to chemicals and environmental influences

Contact 

Certifications & Approvals



Application

Edge protection grommets are used wherever cable and wires are routed through apertures. HellermannTyton grommets offer excellent mechanical protection.

Edge protection grommets is suitable for following markets and industries



More products in this product group

Edge protection grommets >

Base Data

		^
Cable Ø max	5.0 mm	
Cable Ø min	4.0 mm	
Colour	Black (BK)	
Pack Cont.	2000 pcs.	
Package Quantity per	pcs.	
PART DESCRIPTION	HV1201-PVC-FR-BK	
Product Family	Edge protection grommets	
Product Group	Edge protection grommets	
Short Description	Edge protection grommets black	
Variant	Closed	

Product Dimensions

		^
Bundle Ø max.	9.5 mm	
Diameter (D)	4.0 mm	
for Hole Ø (FH)	6.4 mm	
Height (H)	5.6 mm	
Height (H2)	1.6 mm	
Outside Ø (OD)	9.5 mm	
Shore Hardness A	55±5	

Material and Specifications

		^
ELV compliant (Article 4 - 2)	YES	
Flammability	UL 94 V0	
Hazardous good	No	
Material	Polyvinylchloride, flame retardant (PVC-FR)	
Nato number	5325-12-146-1735	
Operating Temperature - °C	-30 °C to +60 °C	
Specifications		

Contact

Waterproof	No
------------	----

Logistics and Packaging

▼

More Information

▲

ETIM 6.0	EC000879
ETIM 7.0 Key	EC000879

Similar products

▲

HV1101
633-01010
For punched or drilled metal sheets



HV1203
633-02030
Edge protection grommets



HV1204
633-02040
For punched or drilled metal sheets



HV1205
633-02050
For punched or drilled metal sheets



HV1206
633-02060
For apertures



HV1207
633-02070
For apertures



Show all ▼